


MEDO 60 CW

CORONA, LED Outdoor surface-mounted wall and ceiling light, DALI, silver-grey, 3000/4000K

The high quality MEDO CORONA supplements the MEDO series, and impresses with its well thought-out new features: Thanks to its homogeneous, indirect upwards light emission, it generates a decorative Corona effect. A practical switch that provides flexibility, and with the MEDO CORONA variant is easy to switch between 3000K and 4000K. The MEDO CORONA also excels during installation: The base plate is screwed to the wall or the ceiling, then the body is simply attached to the socket using three clips and can be removed in the same way, of course. The ceiling light can be converted into a pendant using a suspension kit, and is therefore also ideal for rooms with high ceilings. The built-in LED driver makes direct connection to a 120V to 240V mains supply possible.

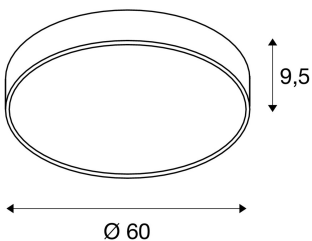

TECHNICAL DATA

Item no.:	1001899
Primary nominal voltage	220-240V ~50/60Hz mA/V
Secondary power / secondary voltage	1000 mA/V
Height	9.5 cm
Diameter	60.0 cm
Net weight	4.5 kg
Gross weight	4.815 kg
Safety class	I
Assembly	Surface
Assembly details	Ceiling, Wall
Dimmable	Ja
Dimming technology	DALI
Wattage	40.0 W
Lumen	4870 lm
Beam angle	105 °
CRI	>80
UGR ?	25
Binning	3
Service life	25000 h
BIG WHITE Page	96

Accessories

1001950	MEDO 5m suspension , white
1001951	MEDO 5m suspension , silver-grey
1001952	MEDO 5m suspension , black
135250	SUSPENSION SET , for MEDO round pendant, round, black, 5-wire
135251	SUSPENSION SET , for MEDO round pendant, round, white, 5-wire
135254	SUSPENSION SET , for MEDO round pendant, round, silver-grey, 5-wire

Notes
