




## MEDO RING 60 DALI

Indoor LED pendant, white, 3000K

As well as having an appealing design, the modern MEDO RING impresses with efficient and powerful LED modules that are also dimmable. The aluminium frame is fitted with an acrylic glass cover which provides bright and uniform illumination. Its 1.5 metre pendant length makes it ideal for rooms with high ceilings. The built-in LED driver makes direct connection to a 120V to 240V mains supply possible.

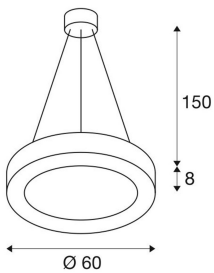

### TECHNICAL DATA

Item no.:	1002891
Primary nominal voltage	220-240V ~50/60Hz mA/V
Secondary power / secondary voltage	700 mA/V
Pendant length	150.0 cm
Height	8.0 cm
Diameter	60.0 cm
Net weight	4.968 kg
Gross weight	6.223 kg
Safety class	I
Assembly	Surface
Assembly details	Ceiling
Dimmable	Ja
Dimming technology	DALI
Wattage	34.0 W
Lumen	2095 lm
Colour temperature	3000 Kelvin
Beam angle	105 °
CRI	>80
UGR ?	22
Binning	6
Service life	20000 h
Minimum ambient temperature	-25 °C



Maximum ambient temperature	40 °C
BIG WHITE Page	101

**Notes**

---

---

---

---

---