




## ESKINA SENSOR

Outdoor surface-mounted wall and ceiling light, anthracite, 3000/4000K, IP65, dimmable

A new family in the SLV lighting world! We are providing you with an integrated outdoor lighting solution with the ESKINA family. Regardless of whether it is a floor stand, a wall and ceiling light or a display fitting. You will find the right light for any application. All of the luminaires can be operated with 3000 K or 4000 K. Versions with motion sensors are also available.

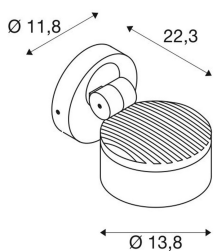

## TECHNICAL DATA

Item no.:	1002904
Primary nominal voltage	220-240V ~50/60Hz mA/V
Secondary power / secondary voltage	350 mA/V
Vertical tilting range	105 °
Horizontal rotation range	340 °
Height	22.3 cm
Diameter	13.8 cm
Net weight	1.261 kg
Gross weight	1.478 kg
IP Code	IP 54
Safety class	I
Impact resistance class	IK02
Impact resistance	0,20000000000000001 Joule
Assembly	Surface
Assembly details	Wall
Dimmable	Ja
Dimming technology	trailing edge
Number of through-wires	20
Wattage	14.5 W
Lumen	1000 lm
Beam angle	95 °
CRI	>80



Binning	6
Service life	36000 h
Ambient temperature	25 °C
BIG WHITE Page	689

**Notes**

---

---

---

---

---