




Follow us @DJIglobal
dji.com

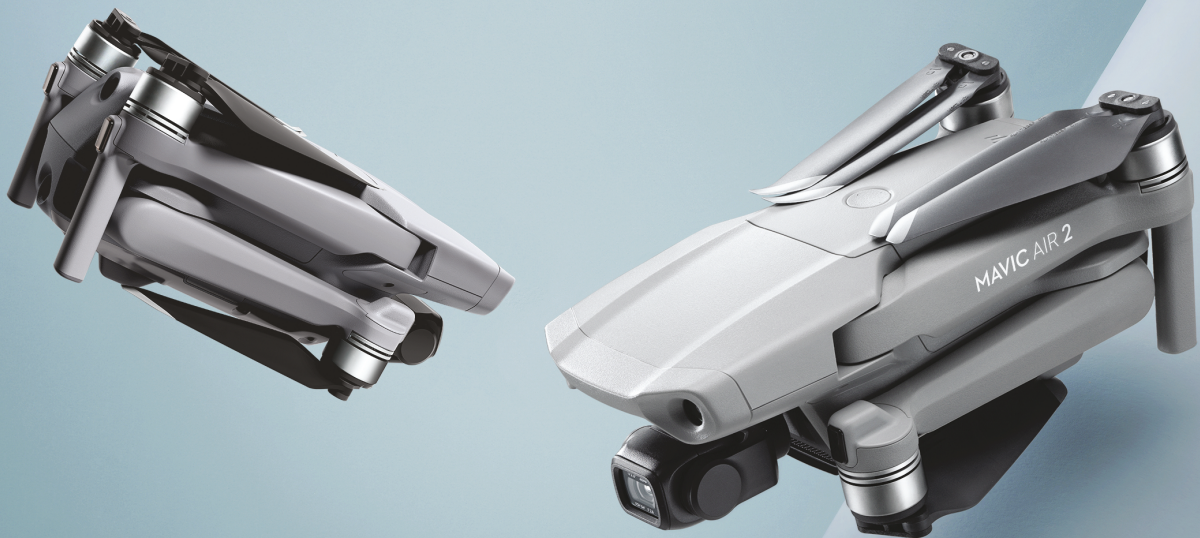

MAVIC AIR 2

Up Your Game



48MP Photo
4K/60fps Video



10km Max
Transmission
Distance



34-Min
Max Flight Time



HDR



FocusTrack



8K Hyperlapse

Camera Quality

- Photo: 48 MP | SmartPhoto
- Video: 4K/60fps | 120 Mbps | 1080p/240fps Slow Motion
- HDR: Photo | Video | Panorama
- Parameters: 1/2-inch CMOS Sensor | HEVC (H.265) | f/2.8 Aperture

Flight & Safety

- Flight: 34-Min Max Flight Time | 68kph Max Speed
- OcuSync 2.0: 10km Full HD Video Transmission ^[1] | Anti-Interference 2.4/5.8 GHz
- APAS 3.0 Obstacle Avoidance
- Obstacle Sensing: Forward | Backward | Downward
- Auxiliary Light

Intelligent Functions

- FocusTrack: ActiveTrack 3.0 | Spotlight 2.0 | Point of Interest 3.0
- QuickShots: Dronie | Circle | Helix | Rocket | Boomerang | Asteroid
- Hyperlapse: Free | Circle | CourseLock | Waypoint

Remote Controller & App

- DJI Fly App: Story Editing Template | Optimized EIS | Easy Sharing
- Remote Controller: Upgraded 240-Min Battery Life | Comfortable Grip

1. Unobstructed, free of interference, when FCC-compliant. Maximum flight range specification is a proxy for radio link strength and resilience. Always fly your drone within your visual line of sight unless otherwise permitted.