


PARTS OPTION

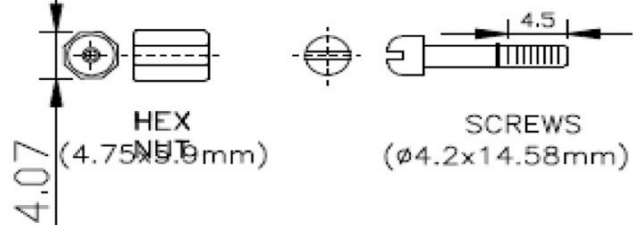

No.	Changes and/or Note No.	Date	Intr.	No.	Changes and/or Note No.	Date	Intr.

SPECIFICATION

MATERIAL

WIRE :PVC WIRE COMPOUND UL1007

Insulator: P.B.T & Glass fill reinforced UL94V-0

Contacts: Brass(standard);Phosphor Bronze(choose)

Shell: **ABS UL94HB Finished Metalized**

Rivet,Boardlock: Brass

CONTACT PLATING

Underplate: 50m" Nickel

Contact area: 1m" Selective Gold

ELECTRICAL CHARACTERISTICS

Operation voltage: 250 VAC max.

Current rating: 3 Amps max.

Contact resistance: 15 mohms max.

Insulation resistance: 3000 Mohms min @ 500 VDC

Dielectric withstanding voltage: 1000 VAC / minute

Operating temperature: -55°C TO +105°C

WIRE SPECIFICATION COUNT		
BLACK	M-F	1
BROWN	M-F	1
RED	M-F	1
ORANGE	M-F	1
YELLOW	M-F	1
GREEN	M-F	1
BLUE	M-F	1
VIOLET	M-F	1
GRAY	M-F	1

DATE	05/11/2012	DRAWN	SCALE	MATERIAL TYPE	
		APPROVED		REPLACES	
		<b>9-way Male to 9-way Female</b> <b>GA-0909-MF-M-K</b>			
				DRAWING No <b>2111-0105-11</b>	