


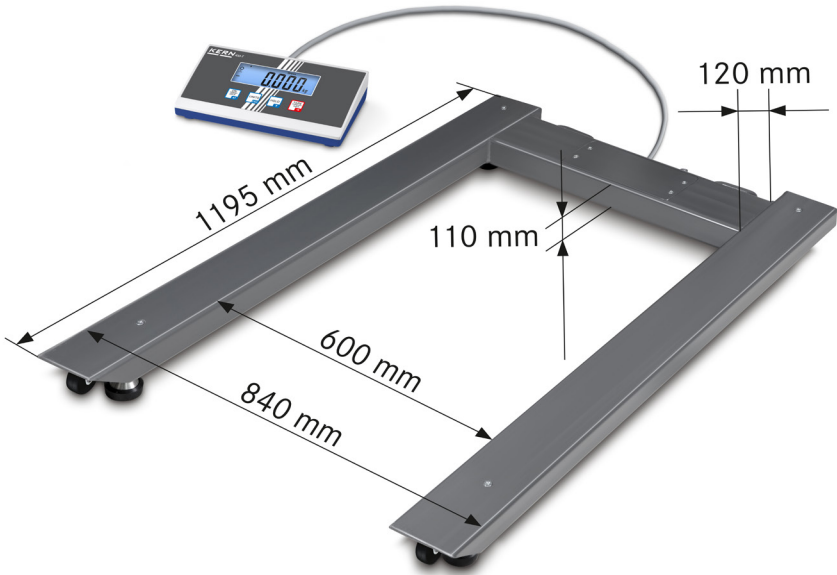

Discover more details and matching accessories online!

Pallet scale with steel load support (IP67) and the best price-to-performance ratio

- Features**

 - Thanks to battery operation, compact, light-weight construction, it is suitable for the use in several locations
 - Load support: steel, powder coated, 4 silicone-coated aluminium load cells, protection against dust and water splashes IP67
 - **1** The scale can be easily transported using rollers and a handle and does not require much storage space
 - Protective working cover included with delivery
 - **2** Our floor scales are delivered in a robust wooden box. This protects the high-quality weighing technology from environmental influences and stresses during transportation
- Technical data**

 - Large LCD display, digit height 25 mm
 - Dimensions of display device W×D×H 235×114×51 mm
 - Cable length of display device approx. 5 m
 - Optional battery operation, 4×1.5 V AA not included in scope of delivery, operating time up to 60 h
 - Net weight approx. 55 kg
 - Permissible ambient temperature -10 °C/40 °C

Shipment via freight forwarder. Please ask for dimensions, gross weight, shipping costs

STANDARD



OPTION



Model	Weighing capacity	Readability	Options
			Calibr. Certificate
KERN	[Max] kg	[d] kg	DAkkS accr. KERN
UIB 600K-1	600	0,2	963-130
UIB 1.5T-4	1500	0,5	963-130
UIB 3T-3	3000	1	963-132