



► (RTS) Bayonet Bore Type
RTS. (1000)

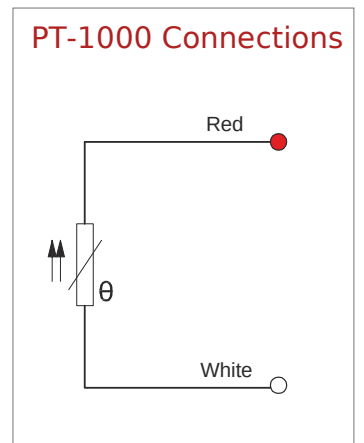

Max. operating temperature : -50 °C / +200 °C
 Standard cable types : Silicone + Silicone
 Sensor type : DIN/EN60751 Class "B" 1xPT-1000
 Protection tube material: AISI304 (DIN1.4301) Stainless Steel

► Technical drawing

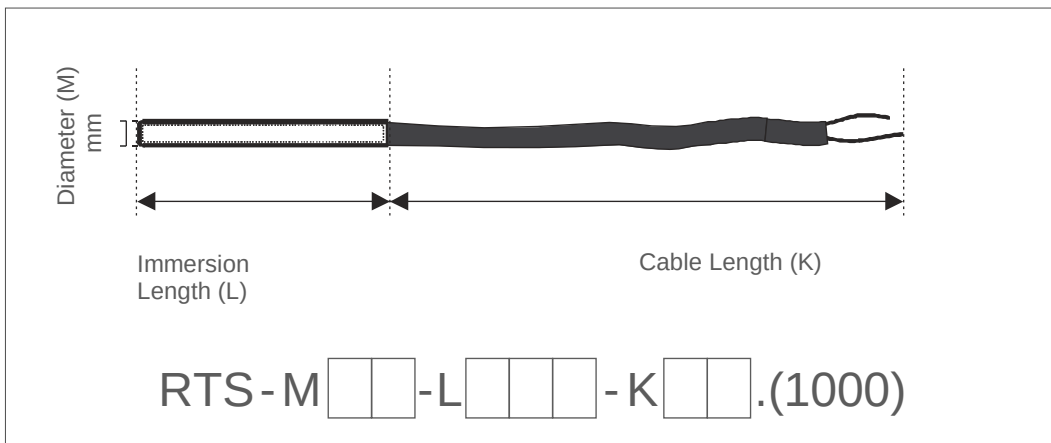

Diameter (M) :
 Immersion Length (L) :
 Cable Length (K) :