

Specification

CS 1-5 L

5-way HDMI Switch 4K@30Hz

with IR- remote control, with external IR-receiver

5 inputs, 1 output

Multi-switching methods: IR remote or by touch button

supports 4K (2160P@30Hz), 3D and Full HD (1080p)


supports uncompressed audio such as LPCM

supports HDCP

supports 16 bit per channel (48bit all channel) deep color

supports 340 MHz / 3.4 Gbps per channel (10.2 Gbps all channel) bandwidth

incl. switch, IR receiver cable, remote control and USB cable for power supply (not required for most device combinations)

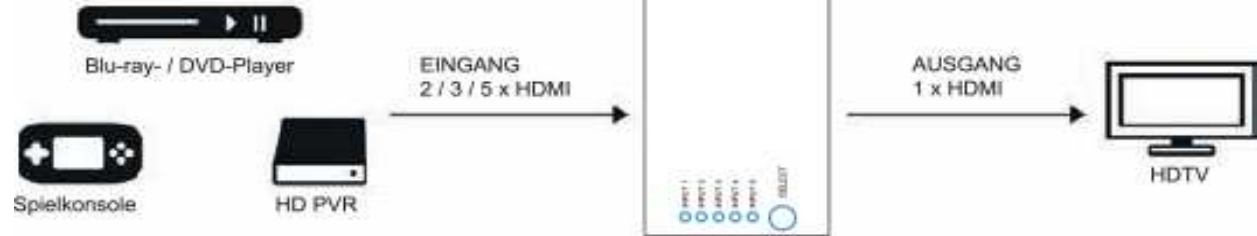

USB cable: 50cm

DC plug: Ø3,5 x Ø1,3 x 10mm

The reproduction, distribution and utilization of this document as well as the communication of its contents to others without explicit authorization is prohibited. Offenders will be held liable for the payment of damages. All rights reserved in the event of the grant of a patent, utility model or design.

本文未经许可不得转让及翻印，不允许引用或转载其内容，违者必纠，并须赔偿损失。保留专利及试样注册的所有权。

REACH: Must be fully comply with EC 1907/2006 concerning the Registration, Evaluation, Authorization, and Restriction of Chemicals (REACH) and must not contain any of the Substances of Very High Concern (SVHC) above the specified concentrations, as defined in Article 57 and Annex XIV (including all amendments) or any of the restricted substances, as defined in Article 67 and Annex XVII (including all amendments).

VerpackG: According to the Packaging Act (VerpackG), the cumulative concentration of lead, cadmium, mercury and hexavalent chromium does not exceed 100 mg per kg.

RoHS: All Materials must be in accordance with 2011/65/EU and 2015/863/EU.

	Date	Name	Designation:
Prep.:	24.07.20	K.B	HDMI switch
Check.:			
Rev.:			
Approv.:			
transmedia <small>keep in contact</small>			TRANSMEDIA-No.: CS 1-5 L
			Page: 1 Page tot.: 1

24.07.2020

X Rosenzweig

Signiert von: transmedia.rosenzweig

Rev.0 OK 24.07.2020 Ro