



RoHS Compliant

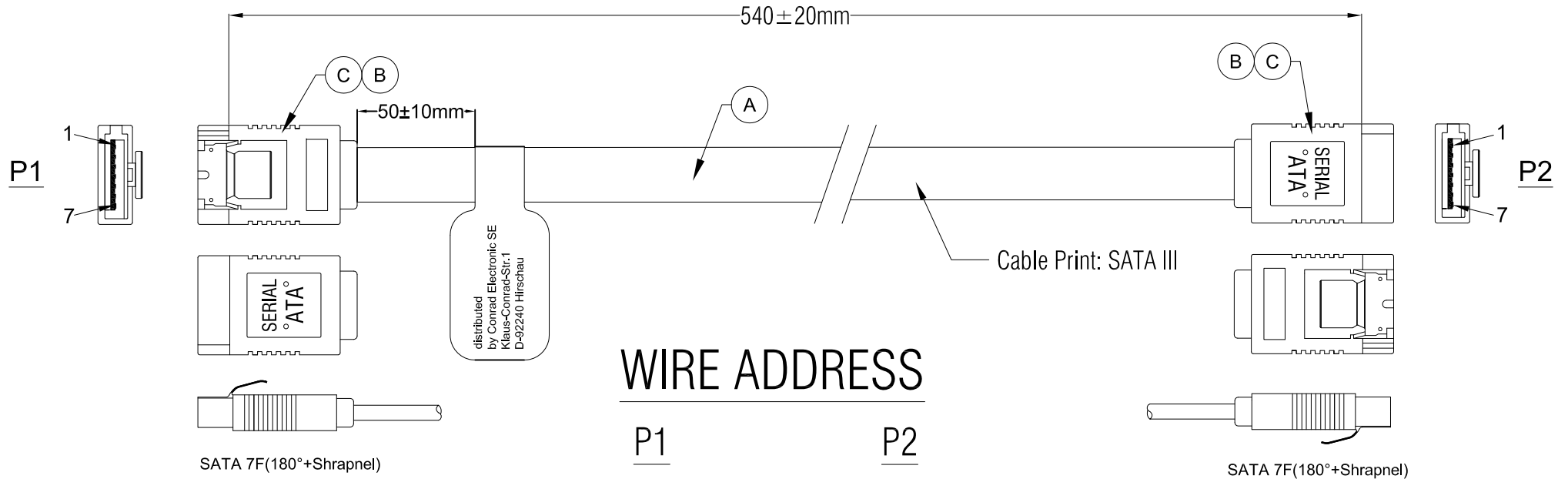

WIRE ADDRESS

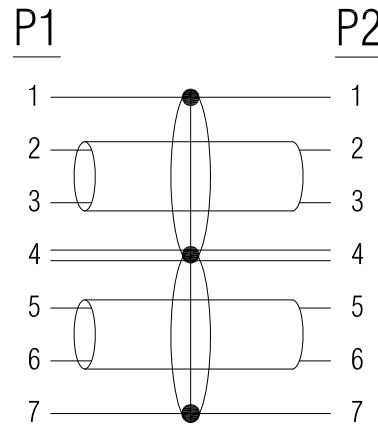


Electrical Test:
1.100% TEST OPEN SHORT MIS-WIRE.
2.CONTACT RESISTANCE:3Ω MAX.
3.INSULATION RESISTANCE:5MΩ MIN.
4.HI-POT:300V DC/10MS.

D		
C		
B		
VER.A	REVISE	DATE
Company: CONRAD		
Item	2269091	
Draw	Kobe	Date: 2020.09.21
Approval		
Duty	F16	BOM.NO: XXXXX
Sample NO.		Drawings of 1 (2) Proportion: 1:1 Unit(mm) A4

C	1	Z-2269091	45P BLACK PVC		G
B			SATA 7P FEMALE(Black Insulator+ Shrapnel)	2	PCS
A			UL2725 or UL21149 26# (2C+AL+2D)*2F, OD=2.3*7.8mm FLAT RED PVC JACKET. Cable Print: SATA III	1	PCS
NUMBER			PRODUCT SPECIFICATIONS	Quantity	Unit

RoHS Compliant

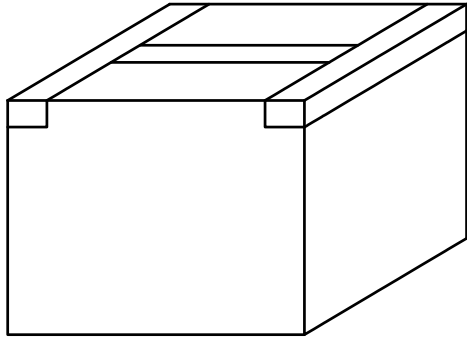

500PCS/CTN (540*370*320mm)

CONRAD
GERMANY
BEST NO.: 2269091
PCS.: 500PCS
MODEL NO.: SATAIII-LTCH-0.5
ORDER NO.:
WEIGHT(KG.): KGS


外箱側麥

CONRAD
HAMBURG
C/NO.:
MADE IN CHINA

外箱正麥

背面沒封口


雙面膠

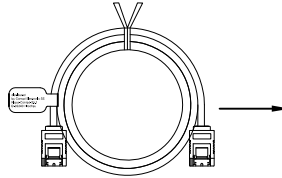



紙袋正面

紙袋背面

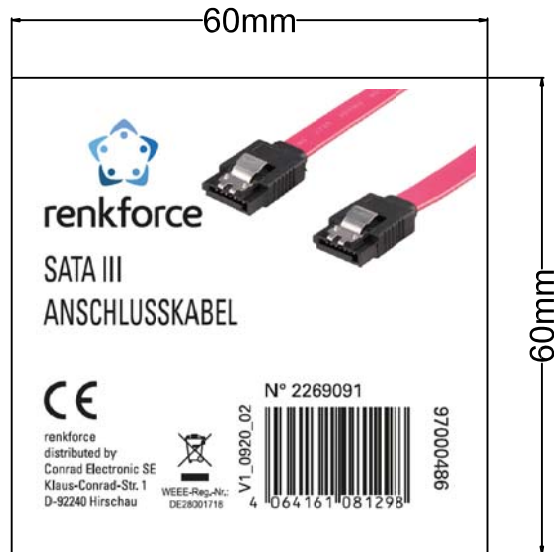1PCS/Kraft paper bag(0.06*150*200mm) + Barcode



Barcode(60*60mm)

D							
C							
B							
VER.A	REVISE	DATE					
Company: CONRAD							
Item	2269091						
Draw	<i>Koke</i> Date: 2020.09.21						
Approval							
Duty	F16 BOM.NO: XXXXX						
Sample NO.		Drawings of 2 (2)	Proportion: 1:1	Unit(mm)			A4