
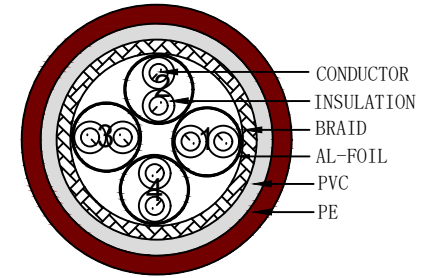


CHART:

ITEM NO.	LENGTH (M)
2269099	10
2269100	15
2269101	20
2269102	30
2269106	40
2269105	50
2269104	60
2269103	75

WIRING DIAGRAM

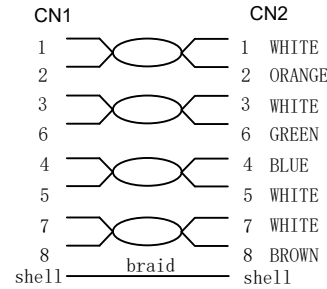

NOTE:

- ELECTRICAL TEST:100% OPEN SHORT, MISS WIRE TEST
- FLUKE Channel LINK TEST:
TEST LIMIT:ISO11801 Channel Class EA
- Working temperature:-40°C~+75°C
Storage temperature:-10°C~+60°C
- RoHS 3.0 AND REACH compliant
- Spray WORD:CAT6A S/FTP 4x2x26AWG/1 PVC+PE ISO11801 & EN50173 & ANSI/TIA568C. 2
- PE: anti-UV(Conform IEC 60811-2-1)
oil resistant(Conform IEC 60811-2-1)
waterproof (Conform IEC 60811-1-3)

MATERIAL LIST:

③	OVER MOLD	PVC 85A Black	2	
②	PLUG	RJ45 8P8C SHIELDED PIN GOLD PLATED 3U", THE SHELL PLATED NICKEL, COLOUR: TRANSPARENT BLUE	2	
①	CABLE	S/FTP CAT. 6A (26AWG/1 BC*1P+AL-FOIL)*4PAIR +Braid(AL-MG)Jacket: PVC+PE BLACK OD:6.0±0.2MM	1	
NO.	PARTS NAME	SPECIFICATION STANDARD	QT' Y	REMARK

Renkforce

					CUSTOMER		BN.				
					PRODUCT NAME		Cat.6A S/FTP 26AWG Solid Patch cord 10G PVC+PE		UNIT	MM	
					NEW	2020-03-20	AO	DRAWNBY	CHECKBY	APPOBY	DATE
BY	CHK	REVISION RECORD MODIFICATIONS			DATE	REV.	Arvin	Alvan	2020-03-20		