



PIN OUT


CN1 CN2

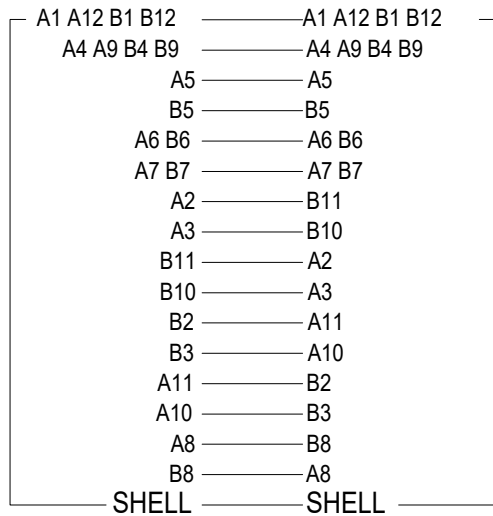

CN1

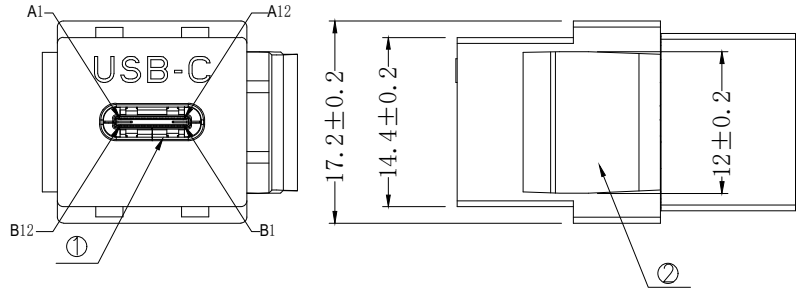

CN2

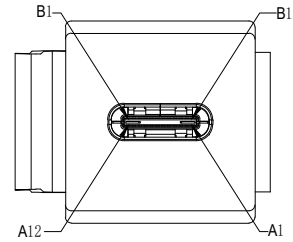

NOTES:

- Electrical test:
 - 100% open short & miss wire test;
 - Insulation resistance:DC 300V 10MΩ Min;
 - Contact resistance:3Ω Max;
- Data Transfer: 10Gbps Voltages:5V Current:3A,
- Support for data and video transmission (Only TYPE C single-sided output is supported)
- Support 3840×2160@60Hz resolution
- Operating Temperature:-25°C~85°C
- Storage Temperature:-20°C~ 70°C
- Operation humidity:10%~85%
- Storage humidity:10%~85%
- RoHS 3.0 and REACH Compliant

MATERIAL LIST:

NO.	PARTS NAME	SPECIFICATION DESCRIPTION	QT'Y	REMARK
②	Housing	ABS	1	
①	TYPE C CONNECTOR	USB C FEMALE, BLACK INSULATION THE PIN GOLD PLATING, THE SHELL FOR NICKEL PLATING WITH PCB	2	
		NEW	2023-03-22	A
BY	CHK	REVISION RECORD MODIFICATIONS	DATE	REV.

FN:	BN.	Housing Color
29212c223PF	2269119	BLACK

Renkforce				
CUSTOMER		BN.		
PRODUCT NAME	USB 3.2 GEN2 Type C female to C Female Adapter		UNIT	MM
DRAWNBY	CHECKBY	APPOBY	DATE	
Hasia	Alvan		2023-03-22	