
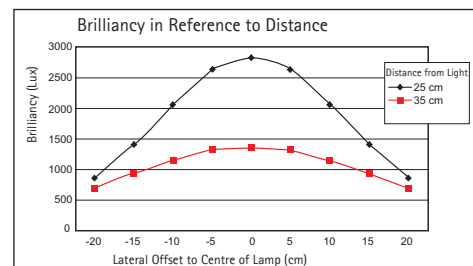
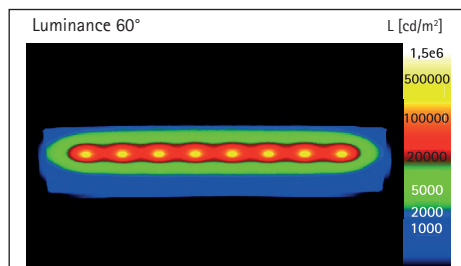


LED Desk Lamp MAULpearly colour vario, dimmable

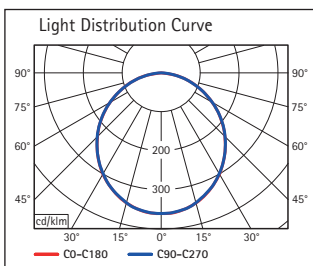

- The powerful compact lamp
- Flexible: colour temperature and illuminance can be adjusted in 3 steps depending on the time of the day and personal needs
- Good illumination of a limited area with strong light need
- Extremely economical : latest LED technology
- Space-saving and easy to handle
- Convenient: stable arm with flexible range for adjustment of the angle
- Technical safety concept Made by MAUL
- With 24 LEDs: 8 warm white (3000 Kelvin) und 16 daylight white (6500 Kelvin)
- This lamp contains built-in LEDs. The LEDs cannot be changed in the lamp
- Life of the LEDs is 20.000 hours
- Energy efficiency class "A+" (spectrum A++ to E)
- Extreme low power consumption of approx. 6 Watt
- Weighted energy consumption 6 kWh/1000h
- 1360 Lux illuminance at 35 cm distance, luminous flux 320 Lumen
- Metal arm with rubber surface, lamp head made of plastic material
- Armlength 35,7 cm
- Height in normal working position 36 cm

- Lamp head, 16 x 6 cm, can be turned and tilted
- Convenient control buttons with touch function on the lamp base
- Stable plastic base, 16,5 x 10,6 cm, with weight inlay and desk protection
- Environment friendly and safe packaging, recyclable
- 820 17 32 and 52: Expected availability from end of May 2020
- Subject to technical adjustments due to EU regulations (EU) 2019/2020 and (EU) 2019/2015. More information is available at www.maul.uk/efficiency/
- Guarantee: 2 year

Art. No.	Colour	EAN Code	Tariff number	Cable length	Protection class	PU	Pack size/cm/PU	Weight/kg
820 17	02 white	4002390069175	94052040	1,7 m	II wall power adapter EU plug	1 pc.	26,5 x 22,0 x 13,5	0,967
820 17	32 atlantic blue	4002390080729	94052040	1,7 m	II wall power adapter EU plug	1 pc.	26,5 x 22,0 x 13,5	0,967
820 17	52 lime	4002390080743	94052040	1,7 m	II wall power adapter EU plug	1 pc.	26,5 x 22,0 x 13,5	0,967
820 17	90 black	4002390079129	94052040	1,7 m	II wall power adapter EU plug	1 pc.	26,5 x 22,0 x 13,5	0,93