
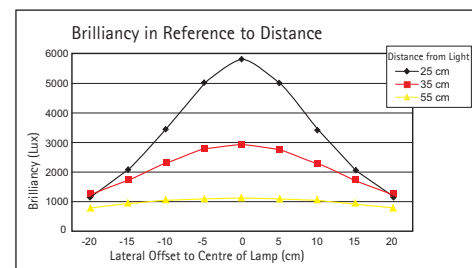
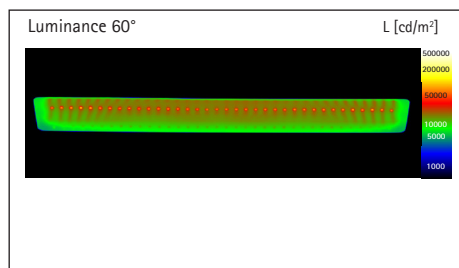
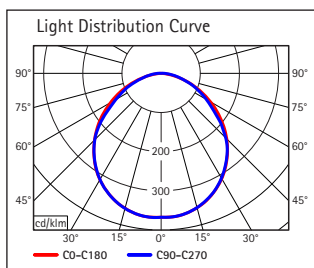
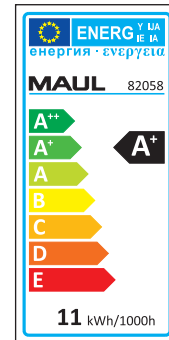


Workstation Lamp MAULintro, dimmable

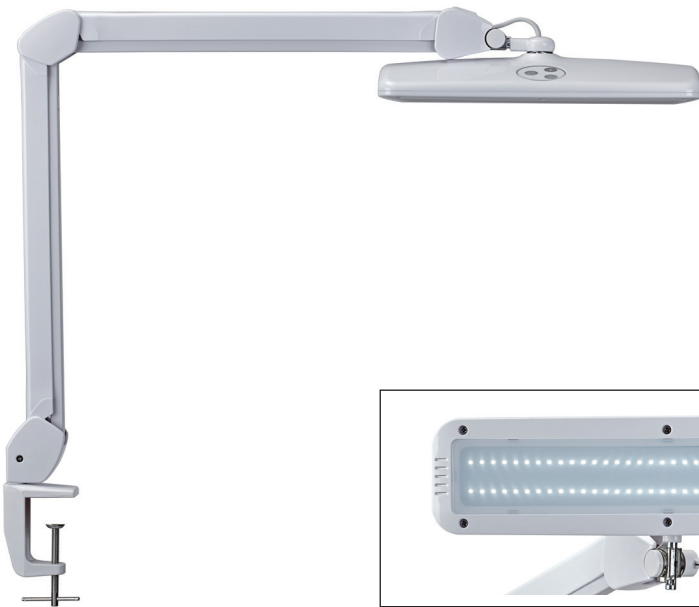

- **Powerful, compact LED lamp**
 - **Convenient: Variably dimmable**
 - **Space saver with good illumination radius**
 - **Powerful and price-attractive model for semi-professional use**
 - **Ideal for precise work e.g. in workshops, for hobbyists, in laboratories or in the field of cosmetics**
 - **Extremely economical: State-of-the-art LED technology, energy efficiency class "A+"**
 - **Technical safety concept Made by MAUL**
-
- 72 high-performance LEDs, 6500 Kelvin, daylight white light
 - This lamp contains built-in LEDs. The LEDs cannot be changed in the lamp
 - The life of the LEDs is 20.000 hours
 - Energy efficiency class "A+" (spectrum A++ to E)
 - Weighted energy consumption 11 kWh/1000 h
 - 2920 Lux illumination at 35 cm distance, luminous flux 920 Lumen
 - Robust metal arm, rotatable by 360°
 - Lower arm length 40 cm and upper arm length approx. 44 cm
 - Height in normal working position 50 cm
 - Three-dimensionally adjustable lamp head
 - Convenient: control button with touch function on the lamp head
 - Clamping foot made of plastic-coated metal, clamping width up to 6,3 cm

- Subject to technical adjustments due to EU regulations (EU) 2019/2020 and (EU) 2019/2015. More information is available at www.maul.uk/efficiency/
- Guarantee: 2 year

Art. No.	Colour	EAN Code	Tariff number	Cable length	Protection class	PU	Pack size/cm/PU	Weight/kg
820 58	02 white	4002390079143	94052040	1,7 m	II wall power adapter EU plug	1 pc.	62,0 x 25,0 x 12,0	2,861