
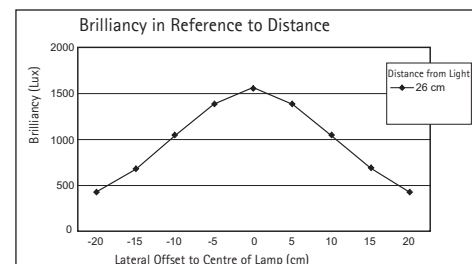
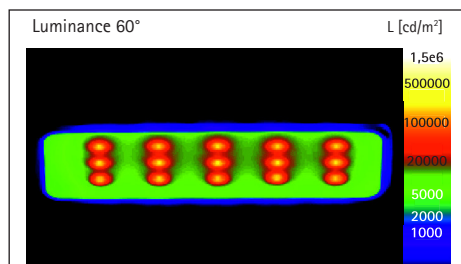


Rechargeable LED Lamp MAULseven colour vario

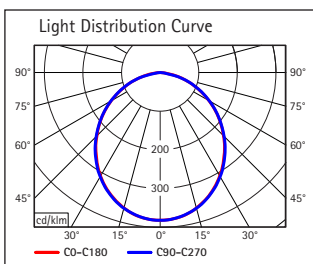

- Pure design: shapely wireless lamp for small spaces, changing workplaces or on the move
 - Off-grid function by rechargeable battery, including micro B USB port and - cable, no disturbing cable
 - Take it wherever light is needed: to the terrace, kitchen table, basement, camper or hotel
 - Can be clapped together saving space, fits in bags and suitcases
 - Colour temperature can be adjusted
 - Extremely economical : modern LED technology
 - Technical safety concept Made by MAUL
-
- With 15 LEDs: 5 warm-white (3000 Kelvin) und 10 daylight white (6500 Kelvin)
 - This lamp contains built-in LEDs. The LEDs cannot be changed in the lamp
 - The life of the LEDs is 20.000 hours
 - Energy efficiency class "A+" (spectrum A++ to E)
 - Low power consumption of approx. 4 Watt
 - Weighted energy consumption 4 kWh/1000h
 - 1560 Lux illuminance at 26 cm distance, luminous flux 210 Lumen
 - Armlength 25,3 cm, Height 27,2 cm, Lamp head, 21,7 x 5 cm, can be tilted
 - Base, 6,2 x 5 cm, with desk protection

- Lithium-ion battery, Battery runtime: approx. 5 hours, charging time: approx. 4 hours
- Convenient control button with touch function on the base
- Micro B USB port on the side of the base
- Including USB cable, length approx. 94 cm
- Can be charged through all standard USB power supplies (1 ampere)
- Size of folded lamp 26,3 x 5 x 6,2 cm
- 818 01 23, 32 and 52: expected availability from mid May 2020
- Subject to technical adjustments due to EU regulations (EU) 2019/2020 and (EU) 2019/2015. More information is available at www.maul.uk/efficiency/
- Environment friendly and safe packaging, recyclable
- Technical safety concept Made by MAUL: each and every luminaire and lamp must pass intensive tests to be included in the MAUL range. Our in-house development team with their optical, electronic and mechanical expertise as well as our knowledge of production technology guarantee the safety of the MAULseven colour vario.
- All plug-in power supplies are disassembled and tested for safety by us
- All luminaires undergo EMC tests during the development phase
- All luminaires undergo endurance testing in our in-house test laboratory
- Guarantee: 2 year

Art. No.	Colour	EAN Code	Tariff number	Weight	Nominal capacity of rechargeable battery	PU	Pack size/cm/PU	Weight/kg
818 01	23 touch of rose	4002390080972	94052040	410 g	1200 mAh	1 pc.	28,5 x 6,8 x 5,5	0,492
818 01	32 atlantic blue	4002390080996	94052040	410 g	1200 mAh	1 pc.	28,5 x 6,8 x 5,5	0,492
818 01	52 lime	4002390081016	94052040	410 g	1200 mAh	1 pc.	28,5 x 6,8 x 5,5	0,492
818 01	71 sahara	4002390069205	94052040	410 g	1200 mAh	1 pc.	28,5 x 6,8 x 5,5	0,492
818 01	84 grey	4002390069199	94052040	410 g	1200 mAh	1 pc.	28,5 x 6,8 x 5,5	0,492
818 01	90 black	4002390069182	94052040	410 g	1200 mAh	1 pc.	28,5 x 6,8 x 5,5	0,492