



#### TECHNICAL INFORMATION

Watts:	42
Input Power:	AC:100-240V, 50/60Hz
Long Life:	20,000 Hours
Unit Color:	Black
Body Type:	ABS Plastic
Operation Temperature:	-35°C to +55°C
Dimmable:	No
Dimension:	119x52x32mm
Output Voltage:	DC:12V
Output Current:	3.5A


#### PLASTIC POWER SUPPLY | LED LIGHTING

V-TAC's LED Lighting range includes lighting that fulfills the needs of various end-users and industries, offering efficient and innovative products that provide modern solutions at an affordable price. We are proud to also provide an extended multi-year warranty on our products, as well as detailed support.

*One brand. endless solutions..*

SKU: 3249 - 42 Black

[View more details](#)

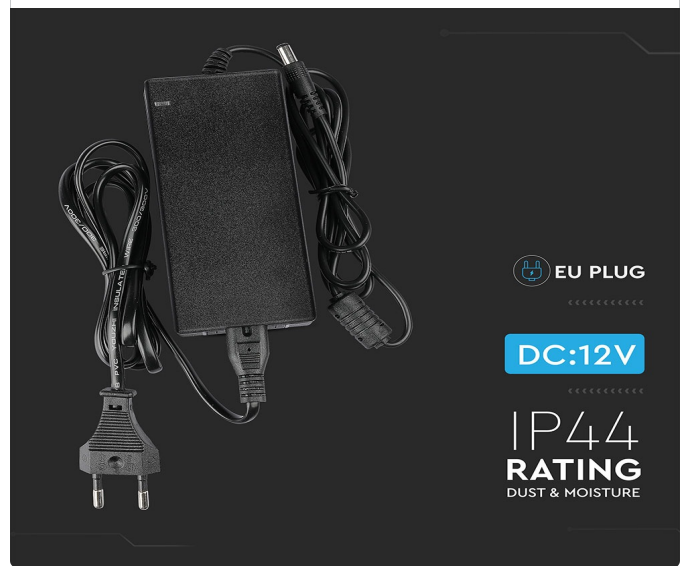

#### FEATURES

- Plastic drivers that are compatible with all V-TAC Strip lights, LEDs etc.
- Short circuit protection, overload protection and stable output voltage
- Built-in EMI Filter
- High efficiency and low temperature
- 100% full load burn-in tested
- IP44 Ingress protection
- CE, EMC approved

CE/EMC

CE/LVD



#### PACKAGING

Gross Weight (Kgs): 0.284  
Unit CBM: 0.000735  
Dimension: 119x52x32mm

#### MASTER BOX PACKAGING

Box Qty: 50  
Qty Per Pallet: 1250  
Length (Box) mm: 140  
Width (Box) mm: 105  
Height (Box) mm: 46

#### LISTING DETAILS

Commodity Code: 8504409090  
Ean Code: 3800157629379