
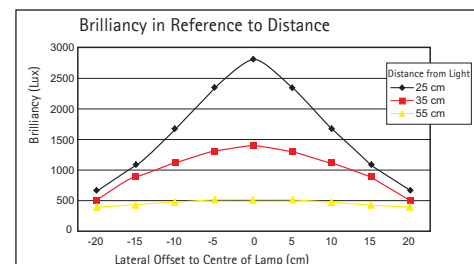
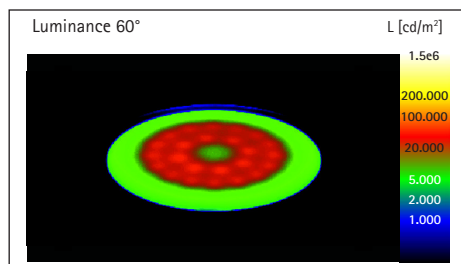
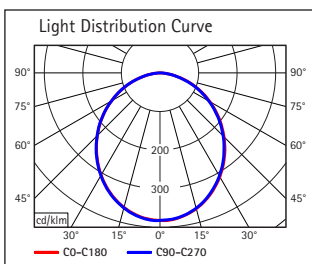


LED Desk Lamp MAULgrace colour vario, dimmable

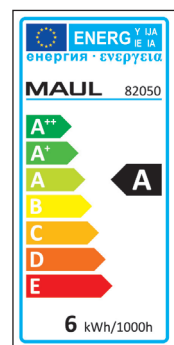

- High-quality design desk lamp with double arm
- Flexible: stepless adjustment of the colour temperature, the illuminance can be adjusted via a 4 step dimmer depending on the time of the day and personal needs
- Modern design: clear lines, reduced to the simple elegance
- Exquisite: arms made of aluminium, brushed and anodised
- Large illumination radius due to long double arm, shadow-free illumination from above
- Extremely economical : latest LED technology
- Technical safety concept Made by MAUL
- Convenient: control buttons with touch function on the lamp head
- With 48 LEDs: 24 warm white light (3000 Kelvin) und 24 daylight white (6500 Kelvin)
- This lamp contains built-in LEDs. The LEDs cannot be changed in the lamp
- The life of the LEDs is 20.000 hours
- Energy efficiency class "A" (spectrum A++ to E)
- Extreme low power consumption of approx. 6 Watt
- Weighted energy consumption 6 kWh/1000h
- 1400 Lux illuminance at 35 cm distance, luminous flux 300 Lumen

- Double joints tilting and rotating
- Upper and lower arm length 36,5 cm each
- Height in normal working position 44 cm
- Lamp head, Ø 11,6 cm, made of plastic with aluminium insert can be turned and tilted
- Stable base, Ø 20,5 cm, with weight inlay and desk protection pad
- Environment friendly and safe packaging, recyclable
- Black version: expected availability from end of May 2020
- Subject to technical adjustments due to EU regulations (EU) 2019/2020 and (EU) 2019/2015. More information is available at www.maul.uk/efficiency/
- Guarantee: 2 year

Art. No.	Colour	EAN Code	Tariff number	Cable length	Protection class	PU	Pack size/cm/PU	Weight/kg
820 50	90 black	4002390081139	94052099	2 m	II wall power adapter EU plug	1 pc.	58,0 x 27,0 x 10,0	3,239
820 50	95 silver	4002390068314	94052099	2 m	II wall power adapter EU plug	1 pc.	58,0 x 27,0 x 10,0	3,239