


LED STRIPS

Item no:VT-5050/30

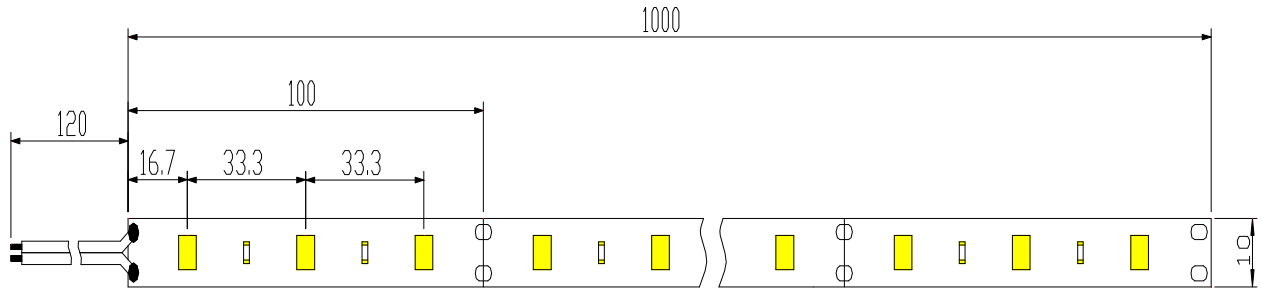

Item No:	VT-5050/30
Real Watts	50W/5M
Voltage	DC 12V
Input Frequency	30/60Hz
Input Current	5A/5M
Lumen/LED	12 lm/LED
Color Temperature	White, Warm White, Red, Green, Blue, RGB
Beam Angle	120°D
LED Chip	SMD 5050
LED Qty	150/5M
Driver	No
Protection Class	IP20/IP65
Body Material	Plastic Cover Back
Unit size	5 Mtr; Width: 10mm
Life Time	20000hrs
Outside using temperature	-25 ~50°C
Packing Method	5mtr roll/packing
Applicable Environment	Indoor Lighting, Used in Home down light, Stairwell lighting.