

MI.SENSOR

Multisensor LS 20.00 pro4




Overview

- Bluetooth brightness, temperature and humidity sensor for müller mi.system
- Only applicable with EA 46.22 pro4!
- Detection of brightness, temperature and rel. humidity
- Mounting capabilities:
 - Mounting on window with vacuum cup for use as a light sensor (included)
 - Wall mounting
 - Integrated in switch design 55 x 55 mm with mounting plate 200.001 (see accessories)
 - Outdoor installation with mounting angle 200.002 (see accessories)
- Compact housing

Order numbers

| | |
|---------------|--|
| ■ müller | |
| LS 20.00 pro4 | Light- / brightness sensor Temperature sensor Rel. humidity sensor |

Accessories

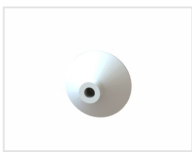

Vacuum cup
200.003



Mounting angle
200.002



Mounting plate for
wall box 200.001

MI.SENSOR

Multisensor LS 20.00 pro4

Technical Data

| | |
|-----------------------------------|---|
| Power supply | via Lithium-Battery CR 2032 IB (included) |
| Measuring range light sensor | 0...65.000 Lux |
| Measuring range temperature | 0...+45 °C |
| Measuring range relative humidity | 0...100 % |
| Permitted ambient temperature | -10...+45 °C |
| Housing | self-extinguishing thermoplastic |
| Mounting | - Window with vacuum cup (included) |
| | - Wall |
| | - In frame (55 x 55 mm) with mounting plate |
| Type of protection | According to DIN EN 60529: IP X1 |
| | IP X4 when mounted with mounting angle |
| Class of protection | III when installed according to regulations |

Rights to technical amendments reserved / Technische Änderungen vorbehalten
Droits de modifications techniques réservés / Suscettibile di errori e modifiche

