


PIN OUT

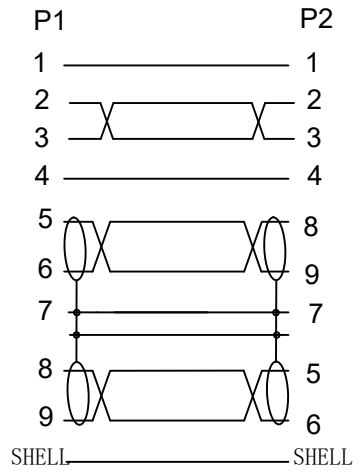

NOTE:

- Electrical test:
 - 100% open short & miss wire test;
 - Data Transfer: Up to 5Gbps
 - Output voltages :5V DC.
- RoHS 2.0 and REACH Compliant
 Operation temperature:-10°C ~+60°C
 Storage temperature:-20°C ~ +75°C
 Operation humidity:10%~85%
 Storage humidity:10%~85%
 Packing:plain box w/Renkforce Sticker

MATERIAL LIST:

NO.	PARTS NAME	SPECIFICATION STANDARD	QT' Y	REMARK
⑥	OUTER MOLD	PVC color For BLACK	1	
⑤	Housing	ABS Housing Black	2	
④	PCB	USB Signal amplifier IC with DC power input	2	
③	USB A TYPE	USB A /F Solder Type,Blue PBT Insulation,The Pin Gold Plating, the shell for Nickel Plating with PCB	1	
②	USB A TYPE	USB A /M Solder Type,Blue PBT Insulation,The Pin Gold Plating, the shell for Nickel Plating	1	
①	CABLE	USB 3.0 28AWG (28AWG BC*1P+E+AL+MYLAR)*2+(25AWG BC*1P)+(22AWG BC*2C)+AEB AL-MG OD:7.0±0.2mm	1	

BN.	F/N	LENGTH
2299173	F/N:29212C333B	10000±200mm
2299174	F/N:29212C333C	15000±200mm

					Renkforce			
CUSTOMER					BN.	See the chart		
PRODUCT NAME	USB 3.0 A male-A female Extension round cable with 2*IC				UNIT	MM		
BY	Hasia	CHECKBY	Alvan	APPOBY		DATE	2021-09-23	
NEW		2021-09-23	A					
REVISION RECORD MODIFICATIONS		DATE	REV.					