

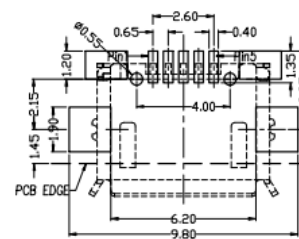
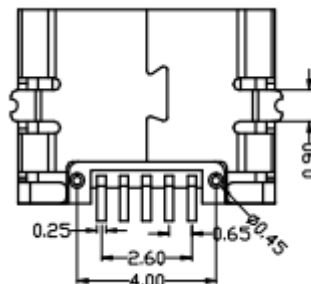
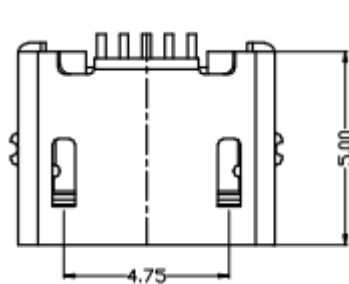
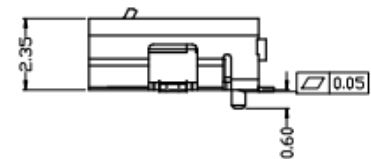


## Data Sheet

### Micro USB socket type B

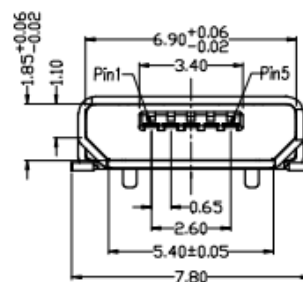

**RECOMMENDED PCB LAYOUT**

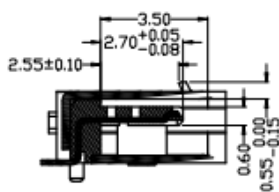

### Technical data

Rate Current: 1A

Dielectric Strength: 100V for 1min

Contact impedance: 50m Ohm max

Insulation impedance: 100M ohm min

Plug life: 10000 cycles

Operation temperature: -30°C ~ +80°C