


## Data Sheet

### Wired SMD LED 0805 Cable



Photo for reference

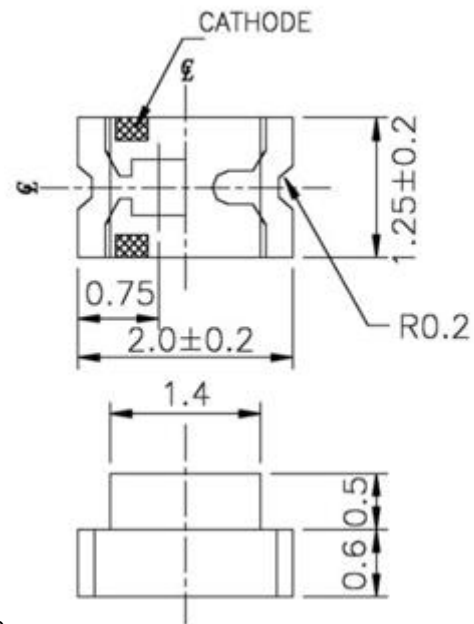

### Technical data

	2300485	2300486	2300487	2300488	2300489
<b>Color</b>	Red	Green	Yellow	Blue	White
<b>UF</b>	2 V	2 V	2 V	3.5 V	3.15 V
<b>IF</b>	20 mA	20 mA	20 mA	20 mA	20 mA
<b>Type</b>	SMD (wired) 0805				
<b>Light intensity</b>	38 mcd	38 mcd	43 mcd	45 mcd	40 mcd
<b>Radiation Angle</b>	140°	140°	140°	140°	140°
<b>Type</b>	Clear	Clear	Clear	Clear	Clear
<b>Length</b>	200 mm	200 mm	200 mm	200 mm	200 mm

Material: copper wire  
 Cross section: appx. 0.0314mm<sup>2</sup>