


Data Sheet

MECHANICAL BUZZER

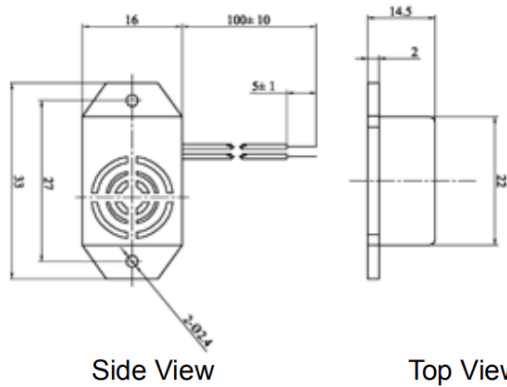

all dimensions are in mm

Technical data

Specifications:

Rated voltage	24VDC
Operating voltage	15V-27VDC
Max Rated current	25mA at 24VDC
Min Sound Pressure Level	75dB at 24VDC/20cm
Resonant Frequency	400±100Hz
Operating temperature	-20°C to +60°C
Storage Temperature	-30°C to +70°C
Housing material/color	ABS/white
Weight	10g