


Data Sheet

MECHANICAL BUZZER

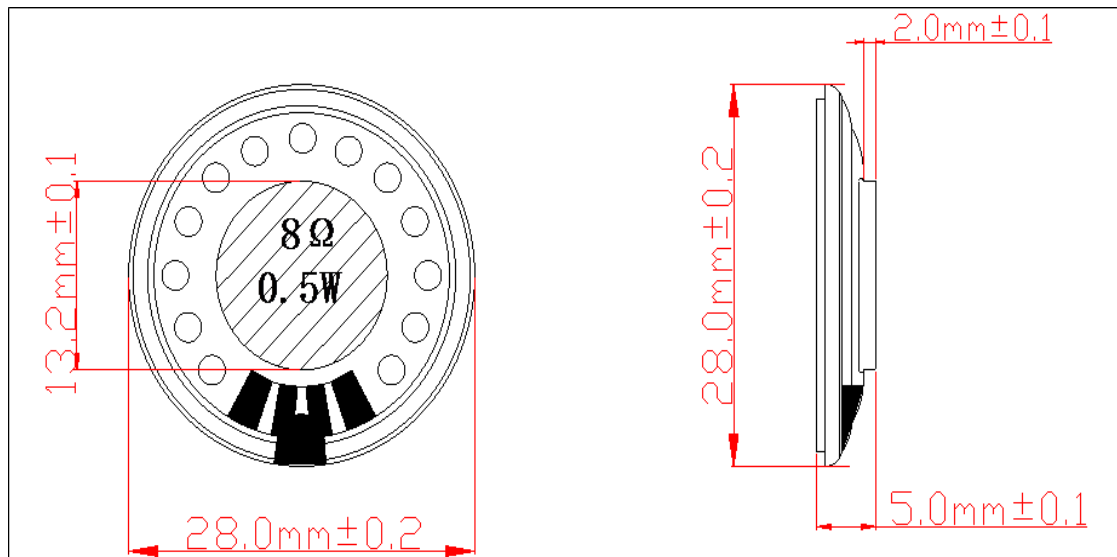

Technical data

Specifications:

Input power	Rated 0.5W/1Wmax
Impedance	$8\Omega \pm 15\%$ (at 2.5 KHz · 1V input)
RESPONSE FREQUENCY	$650 \pm 20\%$ Hz
Sound Pressure Level	88 ± 3 dB SPL /0.1W/0.1m at (1000 、 1200 、 1500 、 2000)Hz AVG
Operating temperature	-30°C to +70°C
Storage Temperature	-40°C to +85°C
Housing material/color	ABS/white
Weight	5.5g

Data Sheet

Frequency Response:

