
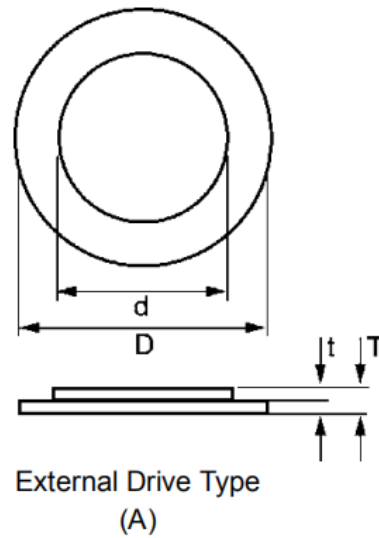


## Data Sheet

### PIEZO ELECTRIC DIAPHRAGM

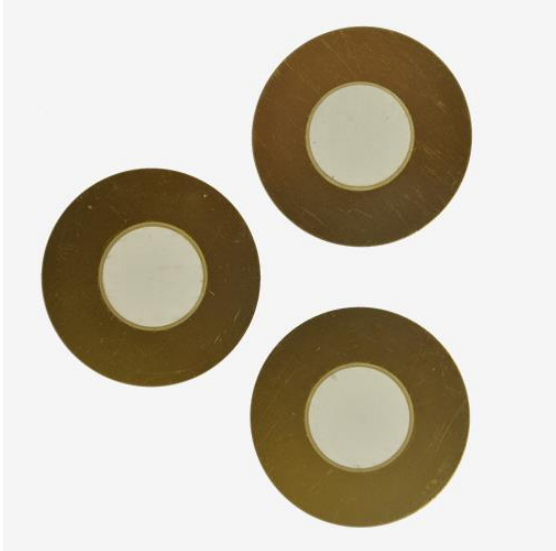

Type A: (D: Ø27mm, d: Ø20mm, T: 0.4mm, t: 0.2mm)

### Technical data

Specifications:

Resonant Frequency	4.0KHz $\pm$ 0.5KHz
Max Resistance (Zr)	300 $\Omega$
Capacitance	25000pF $\pm$ 30%nF at 100Hz