


Data Sheet

PIEZO BUZZER

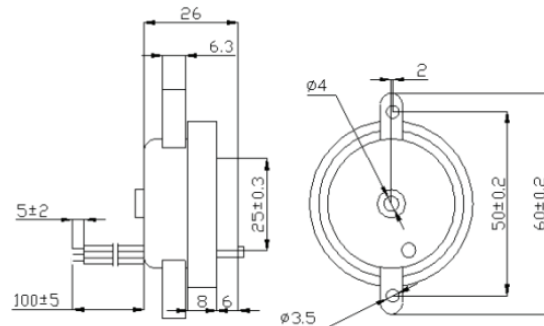

Technical data

Specifications:

Rated voltage	12VDC
Operating voltage	12V-30VDC
Max Rated current	30mA
Min Sound Pressure Level	90dB at 12VDC/10cm
Resonant Frequency	3.2 ± 0.5KHZ
Operating temperature	-20°C to +60°C
Storage Temperature	-30°C to +70°C
Housing material/color	ABS/white
Weight	13g

RED (+12 V) + BLACK: continuous tone

YELLOW (+12 V) +BLACK: continuous tone

Remarks: It is a passive buzzer that requires an external driver circuit