

# WB 59



OEM shark fin styling


GPS/GNSS, MiMo 4G/3G/2G & 3x3 MiMo 2.4/4.9-6GHz

The GPSDC has a compact OEM style shark fin housing that contains 2x2 MiMo antenna function for 4G/3G/2G and an active antenna for GPS/GLONASS/Galileo/Beidou with 26dB gain LNA. Mounted via the integral SMA (f) mount, the PG24-58 portable antenna is a ground plane independent antenna covering 2.4 / 5.0GHz and combined with the two internal dual band WiFi antennas within the GPSDC housing, the antenna is able to offer 3x3 MiMo WiFi (2.4/5.0GHz) in a compact package.

The GPSDC shark fin style design provides multiple antenna functions while remaining discreet and is suitable for public safety (overt/covert), industrial and transport applications where a cost effective, efficient and robust antenna is essential. Requiring only a single hole mounting, the GPSDC reduces vehicle damage, installation time & cost and visual impact whilst protecting a vehicle's resale value.

Technical Drawing

GPSDC-7-27-T24-58 shown

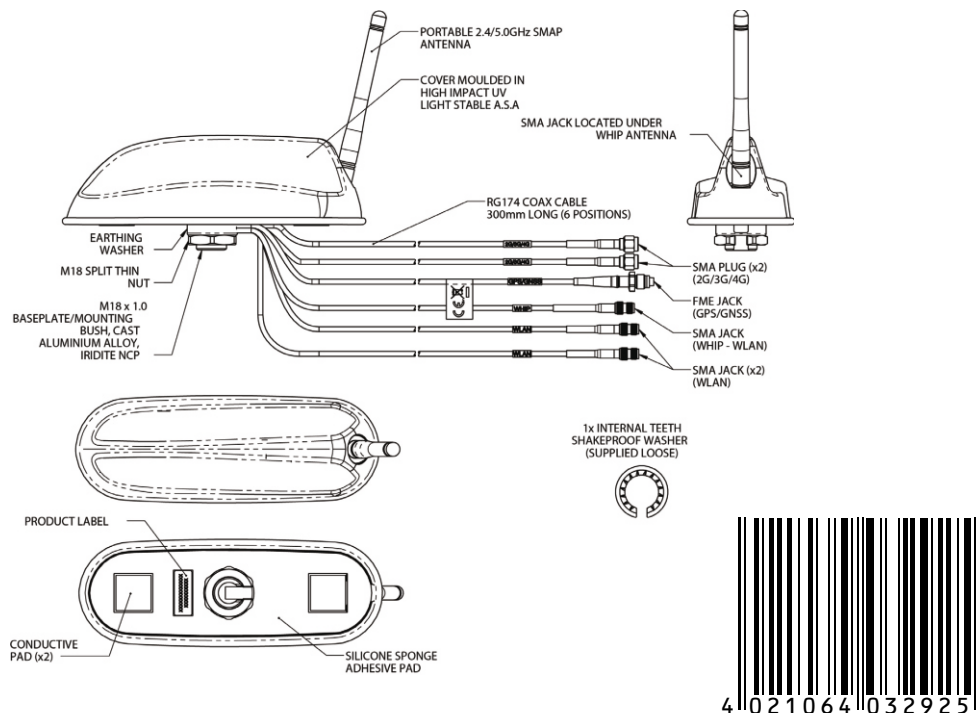

Artikelnummer:103292

Wittenberg Antennen und Zubehör UG, 38723 Seesen  
[www.wittenberg-antennen.de](http://www.wittenberg-antennen.de), Mail: [team@wittenberg-antennen.de](mailto:team@wittenberg-antennen.de)









