



M12 Cat.6A Industrial Patch Cable

Technical Features

Cat.6A Class EA 500 MHz

ANSI/TIA-568.2-D

M12 X-code to RJ45, male to male


S/FTP 26/19 AWG PUR cable

Low smoke and halogen free

UV/oil/flame resistance

IEEE 802.3af, IEEE 802.3at, IEEE 802.3bt (Type 3 & Type 4)

Technical Drawing

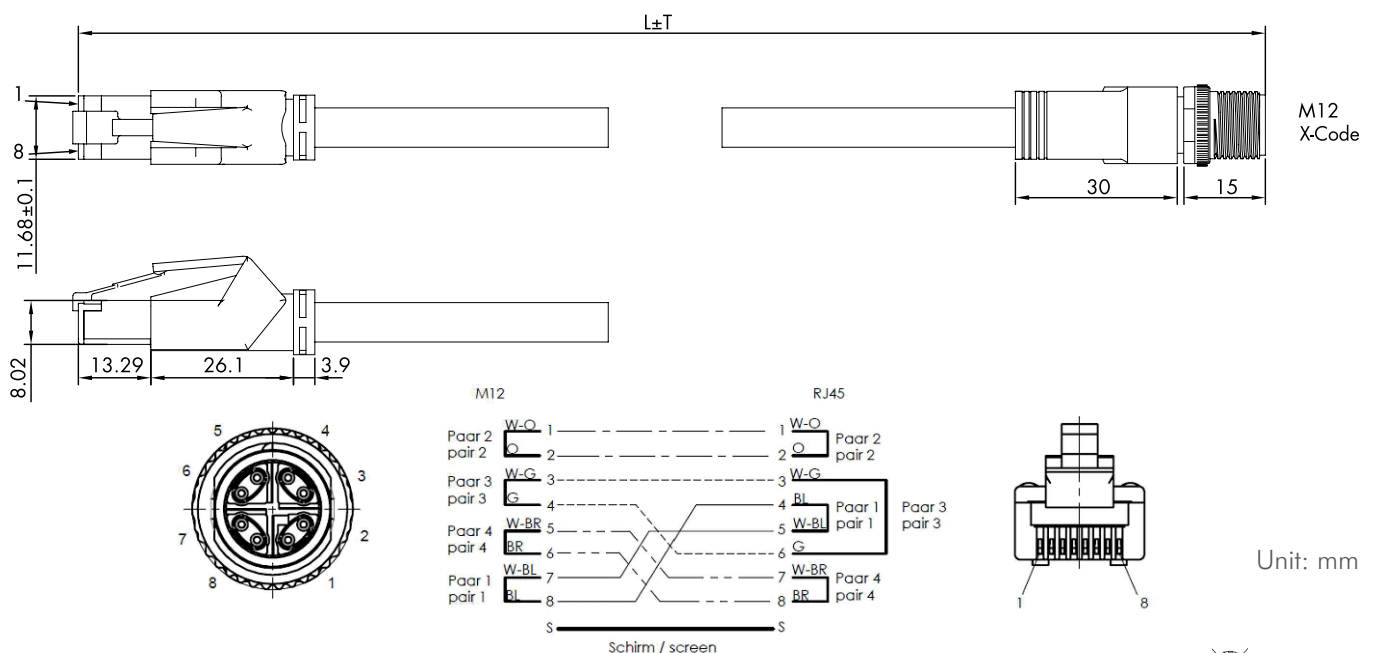

www.2direct.de



Made in China

*The specifications and pictures are subject to change without prior notice.
*All trade names referenced are the registered trademarks of their respective owners.

Art-No.	Cable Length	EAN Code
CQM015S	0.25 m	4052792070545
CQM025S	0.5 m	4052792070552
CQM035S	1 m	4052792070569
CQM045S	1.5 m	4052792070576
CQM055S	2 m	4052792070583
CQM065S	3 m	4052792070590
CQM075S	5 m	4052792070606
CQM085S	7.5 m	4052792070613
CQM095S	10 m	4052792070620
CQM105S	15 m	4052792070637
CQM115S	20 m	4052792070644



Package Content

1x M12 Cat.6A Industrial Patch Cable

Packaging Information

Art-No.	Packing Dimension	Packing Weight	Carton Dimension	Carton Q'ty	Carton Weight
CQM015S	90 x 360 x 5 mm	0.033 kg	400 x 300 x 300 mm	300 pcs	10.5 kg
CQM025S	150 x 200 x 10 mm	0.042 kg	400 x 300 x 300 mm	280 pcs	12.3 kg
CQM035S	140 x 180 x 10 mm	0.068 kg	400 x 300 x 300 mm	200 pcs	14.2 kg
CQM045S	160 x 210 x 10 mm	0.089 kg	400 x 300 x 300 mm	150 pcs	14 kg
CQM055S	150 x 200 x 10 mm	0.108 kg	400 x 300 x 300 mm	100 pcs	11.4 kg
CQM065S	200 x 250 x 20 mm	0.149 kg	400 x 300 x 300 mm	80 pcs	12.5 kg
CQM075S	200 x 250 x 30 mm	0.228 kg	400 x 300 x 300 mm	50 pcs	12 kg
CQM085S	200 x 250 x 30 mm	0.198 kg	400 x 300 x 300 mm	40 pcs	8.5 kg
CQM095S	200 x 250 x 30 mm	0.42 kg	400 x 300 x 300 mm	40 pcs	17.4 kg
CQM105S	250 x 300 x 40 mm	0.62 kg	400 x 300 x 300 mm	20 pcs	13 kg
CQM115S	250 x 300 x 50 mm	0.9 kg	400 x 300 x 300 mm	18 pcs	16.8 kg