


Data Sheet

Push button switch

Version 08/20

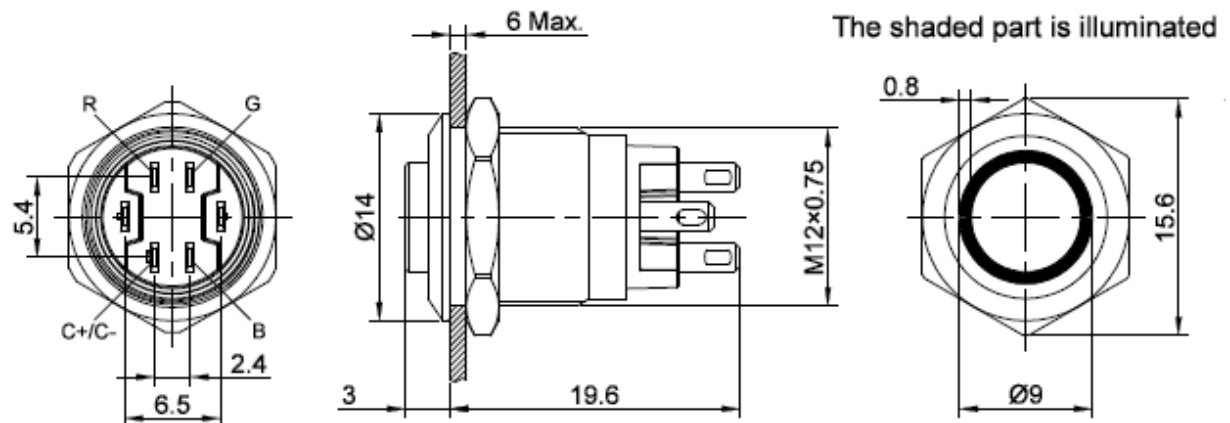

Specification

Mounting diameter	12mm
Head shape	Raised round head
Operation type	Momentary
Contact structure	1NO1NC
Switch rating	2A/48VAC
Illumination type	Ring
LED	RGB 12V(external resistor)
Housing	Stainless steel
Terminal	Soldering Pins
Operating and storage temperature	-25 to +55 °C
IP rating	IP67