


Data Sheet

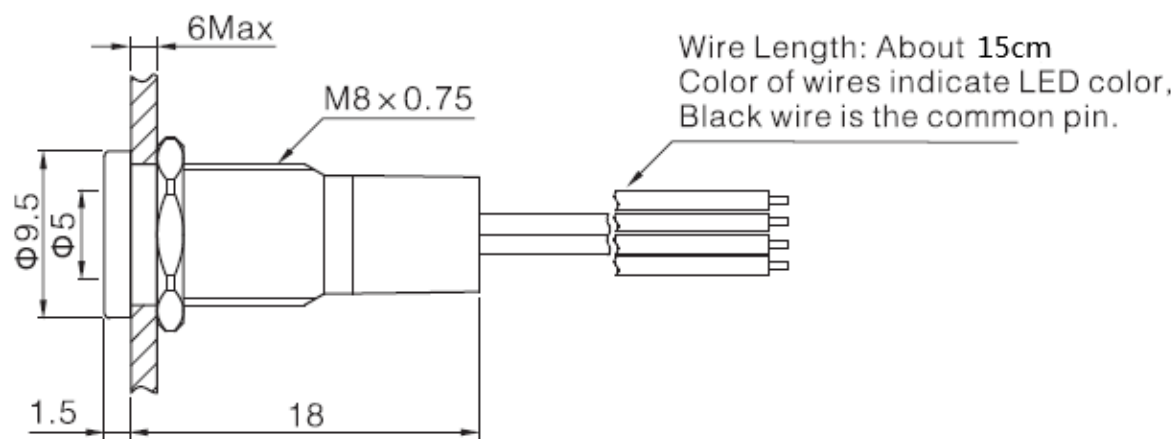

Specification

Mounting diameter	8 mm
LED color	RGB (Cannot mix)
LED voltage	12V~24V
Head shape	Flat head
Body material	Stainless steel
Terminal.....	Wiring (24AWG, about 15cm)
Operating and storage temperature.....	-25 to +55 °C
Led life	40000 hours
Base material	PA
IP rating	IP67