




NEEDED TO START (EXCL.)

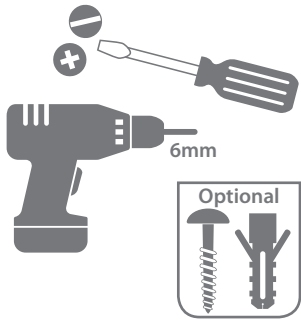


BOX CONTENT | INHALT | CONTENUS | INHOUD DOOS | CONTENUTO | CONTENIDO DE LA CAJA

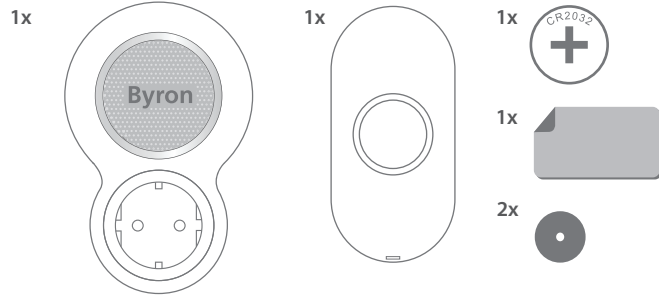


FIRST SET-UP | ERSTEINRICHTUNG | PREMIÈRE CONFIGURATION | EERSTE INSTALLATIE | PRIMO SET-UP | PRIMERA CONFIGURACIÓN

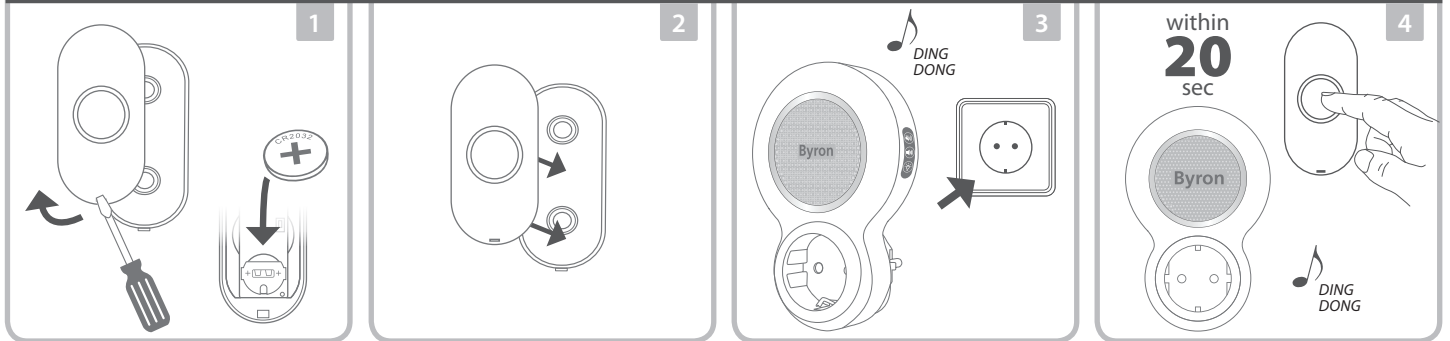


INSTALLATION | INSTALLATION | INSTALLATION | INSTALLATIE | INSTALLAZIONE | INSTALACIÓN

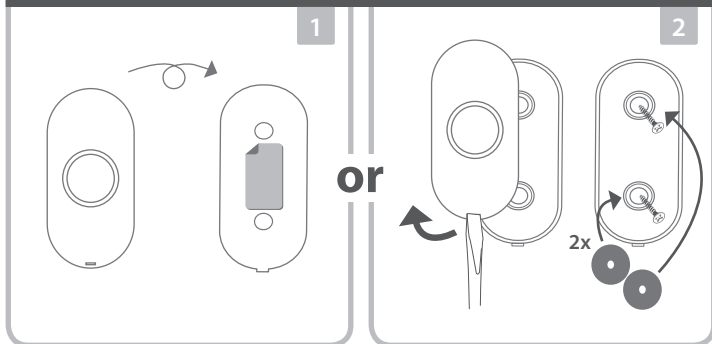


PAIRING MULTIPLE CHIMES | KOPPELN MEHRERER KLINGELN | JUMELAGE DE PLUSIEURS CARILLONS | MEERDERE DEURBELLEN KOPPELEN | ACCOPPIAMENTO MULTIPLO | EMPAREJANDO MÚLTIPLES TIMBRES

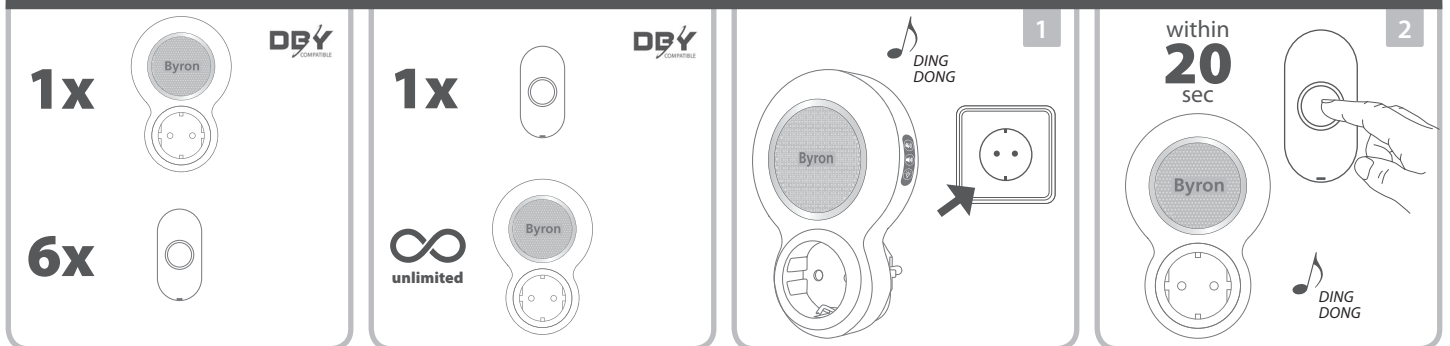


FEATURES | EIGENSCHAFTEN | CARACTÉRISTIQUES | KENMERKEN | CARATTERISTICHE | CARACTERÍSTICAS

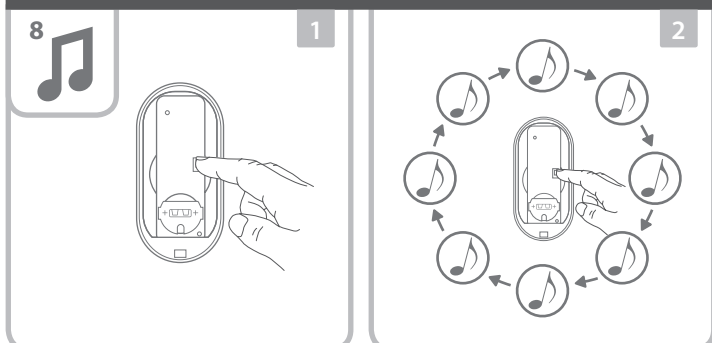

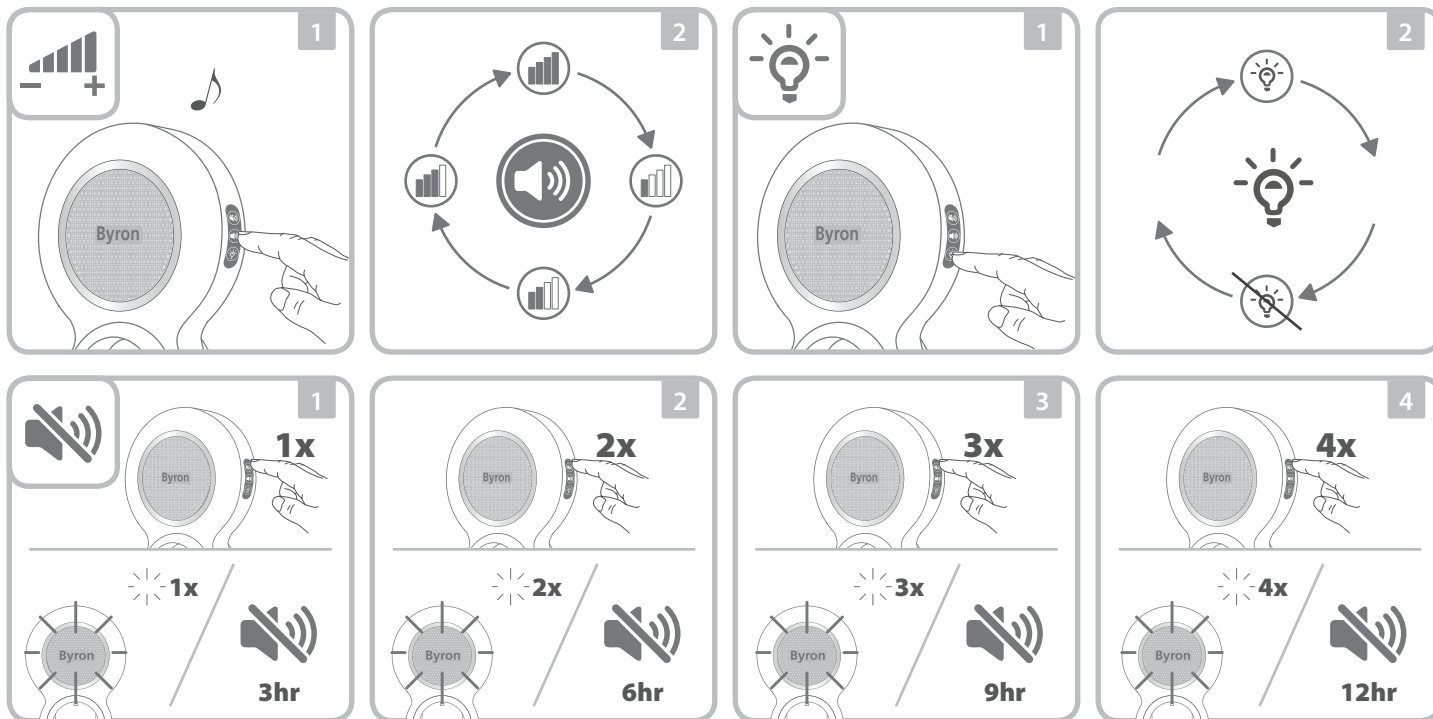

TROUBLESHOOTING | FEHLERBEHEBUNG | RÉSOLUTION DE PROBLÈMES | PROBLEMEN OPLOSSEN | RISOLUZIONE DEI PROBLEMI | SOLUCIÓN DE PROBLEMAS

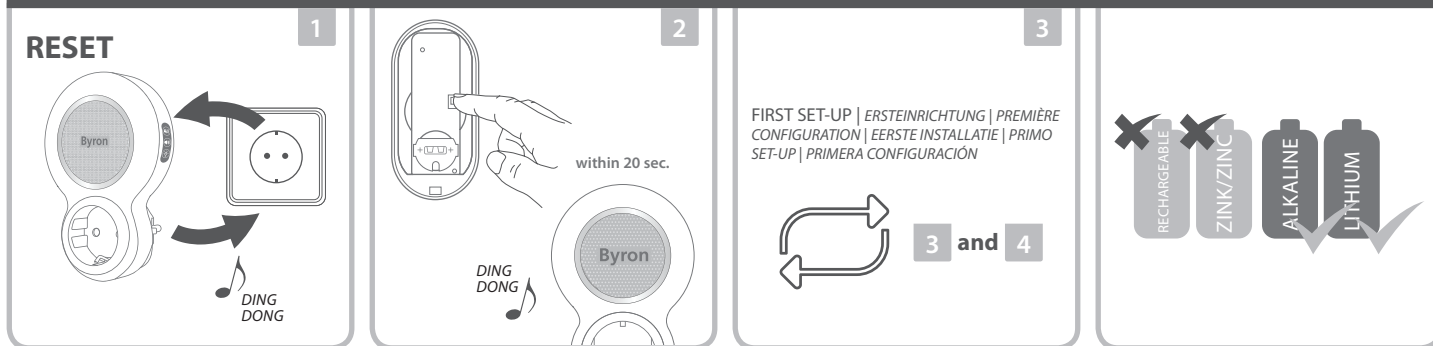

WWW.CHBYRON.EU

Or contact us directly:

smartwares Europe Jules Verneweg 87 5015 BH Tilburg The Netherlands www.chbyron.eu	NL: 088 5940501	Lokaal tarief	CUSTOMER SERVICE
	BE: 078 481094(NL)	Lokaal tarief	
	BE: 078 481540(FR)	Tarif local	
	FR: 0825 560 650	18ct/min	
	DE: +49 (0) 1805 010762	14Ct./Min. dt. Festnetz, Mobil max. 42Ct./Min	
	UK: +44 (0) 345 230 1231		
	ES: +34 938427589		

Find us on

Conforms to all relevant European Directives.

Frequency band: 433.92MHz (433.050 - 434.790 MHz)
 Maximum radio-frequency power: +5.92dB
 Range: 200 meters
 Maximum wattage: 3680W

Wireless Doorbell DBY-23513
 Power: 220-240V – 50 Hz
 Indoor Use Only

Push button - DBY-23510
 Power supply: 1 x CR2032 3V
 IP44 Weather Resistant