




NEEDED TO START (EXCL.)

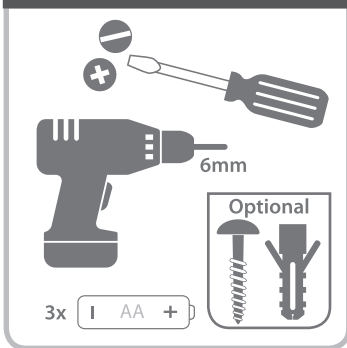


BOX CONTENT | INHALT | CONTENUS | INHOUD DOOS | CONTENUTO | CONTENIDO DE LA CAJA

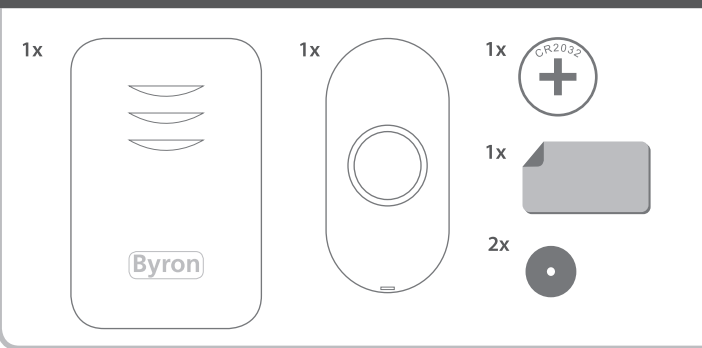


FIRST SET-UP | ERSTEINRICHTUNG | PREMIÈRE CONFIGURATION | EERSTE INSTALLATIE | PRIMO SET-UP | PRIMERA CONFIGURACIÓN

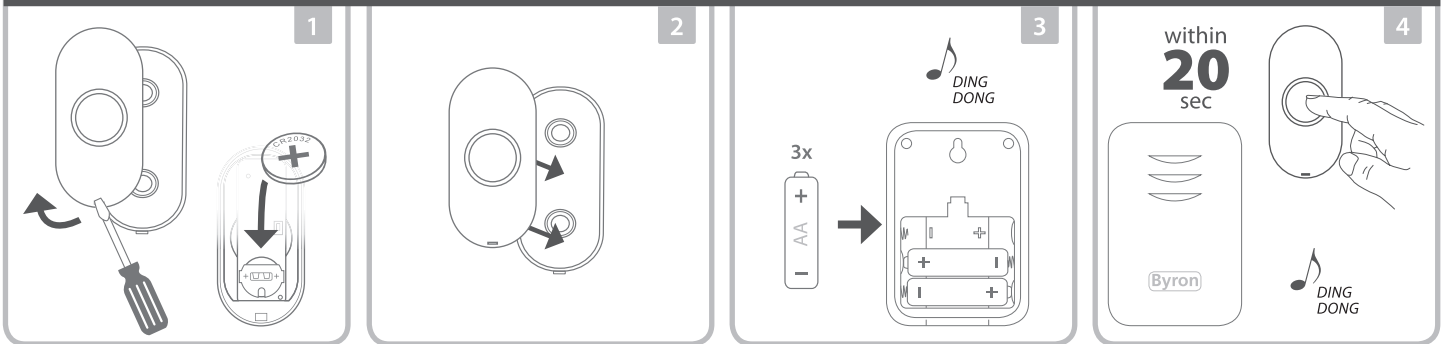

INSTALLATION | INSTALLATION | INSTALLATION | INSTALLATIE | INSTALLAZIONE | INSTALACIÓN

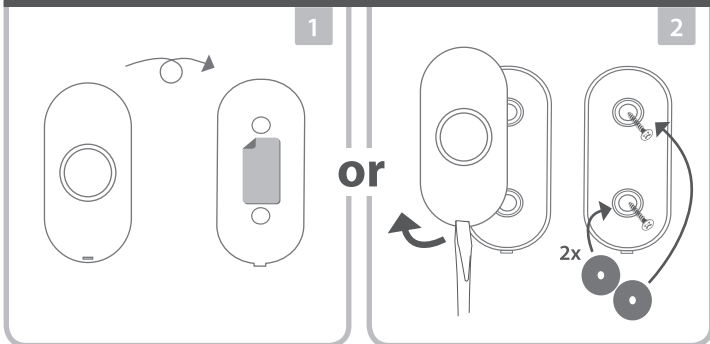

PAIRING MULTIPLE CHIMES | KOPPELN MEHRERER KLINGELN | JUMELAGE DE PLUSIEURS CARILLONS | MEERDERE DEURBELLEN KOPPELEN | ACCOPPIAMENTO MULTIPIO | EMPAREJANDO MÚLTIPLES TIMBRES

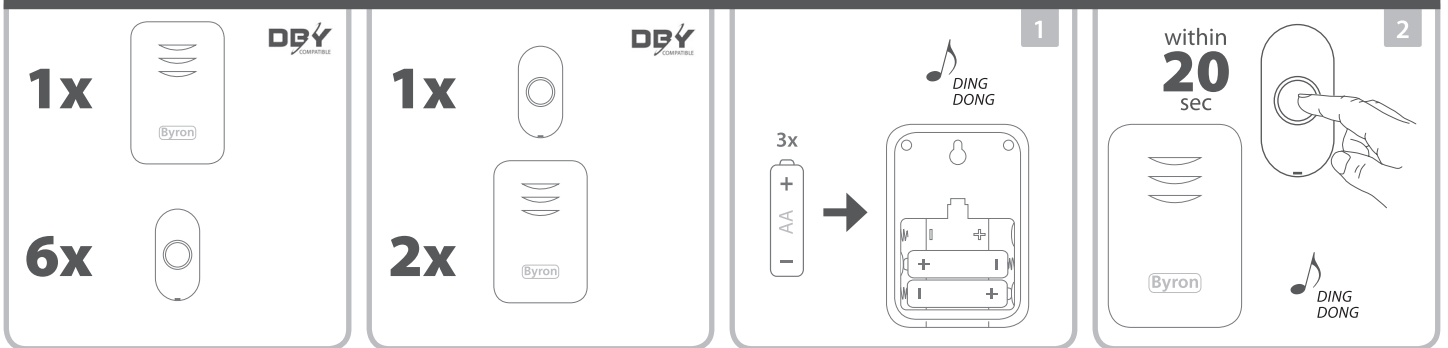


FEATURES | EIGENSCHAFTEN | CARACTÉRISTIQUES | KENMERKEN | CARATTERISTICHE | CARACTERÍSTICAS

	<p>1</p>	<p>2</p>
<p>36</p>	<p>1</p>	<p>2</p>

TROUBLESHOOTING | FEHLERBEHEBUNG | RÉOLUTION DE PROBLÈMES | PROBLEMEN OPlossen | RISOLUZIONE DEI PROBLEMI | SOLUCIÓN DE PROBLEMAS

<p><b>RESET</b></p> <p>1</p> <p>DING DONG</p>	<p>2</p> <p>within 20 sec.</p> <p>DING DONG</p>	<p>3</p> <p>FIRST SET-UP   ERSTEINRICHTUNG   PREMIÈRE CONFIGURATION   EERSTE INSTALLATIE   PRIMO SET-UP   PRIMERA CONFIGURACIÓN</p> <p>3 and 4</p>	
-----------------------------------------------	-------------------------------------------------	----------------------------------------------------------------------------------------------------------------------------------------------------	--

WWW.CHBYRON.EU

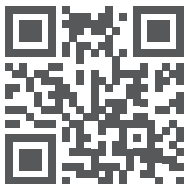

Or contact us directly:

<p>smartwares Europe</p> <p>Jules Verneweg 87 5015 BH Tilburg The Netherlands</p> <p>www.chbyron.eu</p>	NL: 088 5940501	Lokaal tarief
	BE: 078 481094(NL)	Lokaal tarief
	BE: 078 481540(FR)	Tarif local
	FR: 0825 560 650	18ct/min
	DE: +49 (0) 1805 010762	14Ct./Min. dt. Festnetz, Mobil max. 42Ct./Min
	UK: +44 (0) 345 230 1231	
ES: +34 938427589		

CUSTOMER SERVICE

Frequency band: 433.92MHz (433.050 - 434.790 MHz)  
Maximum radio-frequency power: +5.92dB  
Range: 100 meters

**Wireless Doorbell DBY-21131**  
Power: 3 x 'AA'/LR6 1.5V: Total 4.5V  
Indoor Use Only

**Push button - DBY-23610**  
Power supply: 1 x CR2032 3V  
IP44 Weather Resistant

