 




NEEDED TO START (EXCL.)



Optional

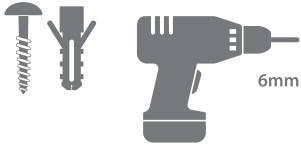

BOX CONTENT | INHALT | CONTENUS | INHOUD DOOS | CONTENUTO | CONTENIDO DE LA CAJA

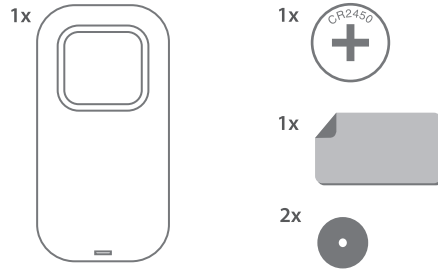

FIRST SET-UP | ERSTEINRICHTUNG | PREMIÈRE CONFIGURATION | EERSTE INSTALLATIE | PRIMO SET-UP | PRIMERA CONFIGURACIÓN

1

2

1x

8x

3

1x

8x

FIRST SET-UP | ERSTEINRICHTUNG | PREMIÈRE CONFIGURATION | EERSTE INSTALLATIE | PRIMO SET-UP | PRIMERA CONFIGURACIÓN

1

2

HOLD → **FLASH**

3

within **20** sec

PUSH

4

+ **PAIRING**

♪ = ✓

INSTALLATION | INSTALLATION | INSTALLATION | INSTALLATIE | INSTALLAZIONE | INSTALACIÓN

FEATURES | EIGENSCHAFTEN | CARACTÉRISTIQUES | KENMERKEN | CARATTERISTICHE | CARACTERÍSTICAS

COLOUR

1

2


3

4

TROUBLESHOOTING | FEHLERBEHEBUNG | RÉOLUTION DE PROBLÈMES | PROBLEMEN OPlossen | RISOLUZIONE DEI PROBLEMI | SOLUCIÓN DE PROBLEMAS

RESET 1



HOLD **10** sec

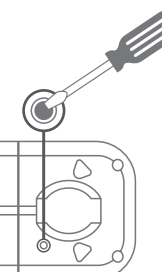


RESET ✓

RESET 1

HOLD **10** sec → **2X FLASH**
within 20 sec.

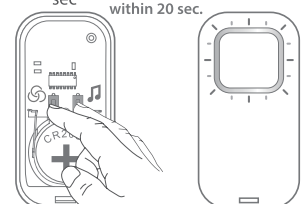
WWW.CHBYRON.EU




Or contact us directly:

smartwares Europe Jules Verneweg 87 5015 BH Tilburg The Netherlands www.chbyron.eu	NL : 088 5940501	Lokaal tarief
	BE : 078 481094(NL)	Lokaal tarief
	BE : 078 481540(FR)	Tarif local
	FR : 0825 560 650	18ct./min
	DE : +49 (0) 1805 010762	14Ct./Min. dt. Festnetz, Mobil max. 42Ct./Min
	UK : +44 (0) 345 230 1231	
	ES : +34 938427589	

CUSTOMER SERVICE

Find us on  **YouTube**



Conforms to all relevant European Directives.

Frequency band: 868.4 MHz
 Maximum radio-frequency power: +5.92dB
 Range: 200 meter

Push button - DBY-25930
 Power supply: 1 x CR2450 3V
 IP44 Weather Resistant

