




NEEDED TO START (EXCL.)

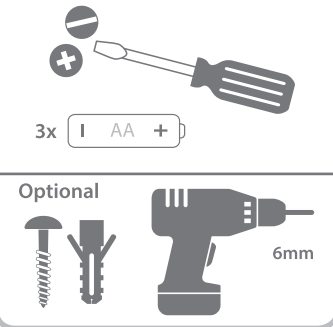


BOX CONTENT | INHALT | CONTENUS | INHOUD DOOS | CONTENUTO | CONTENIDO DE LA CAJA

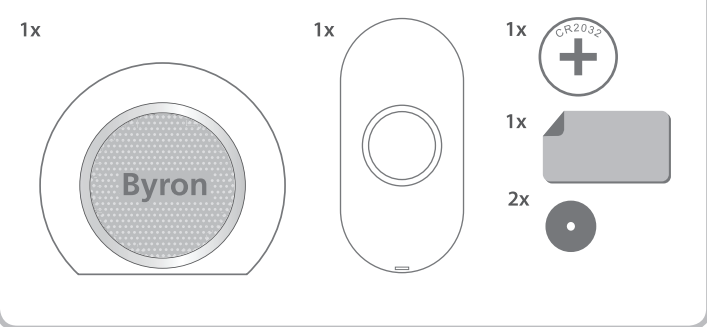


FIRST SET-UP | ERSTEINRICHTUNG | PREMIÈRE CONFIGURATION | EERSTE INSTALLATIE | PRIMO SET-UP | PRIMERA CONFIGURACIÓN

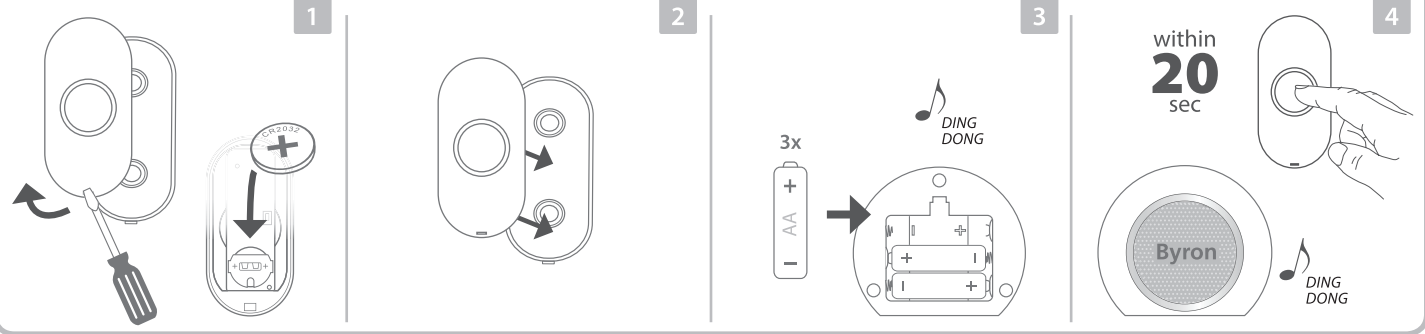


INSTALLATION | INSTALLATION | INSTALLATION | INSTALLATIE | INSTALLAZIONE | INSTALACIÓN

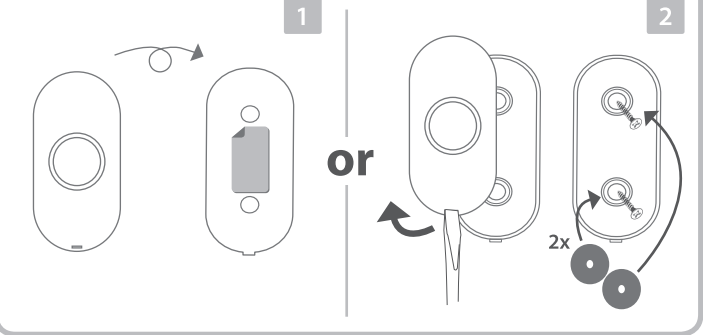

PAIRING MULTIPLE CHIMES | KOPPELN MEHRERER KLINGELN | JUMELAGE DE PLUSIEURS CARILLONS | MEERDERE DEURBELLEN KOPPELEN | ACCOPPIAMENTO MULTIPLIO | EMPAREJANDO MÚLTIPLES TIMBRES

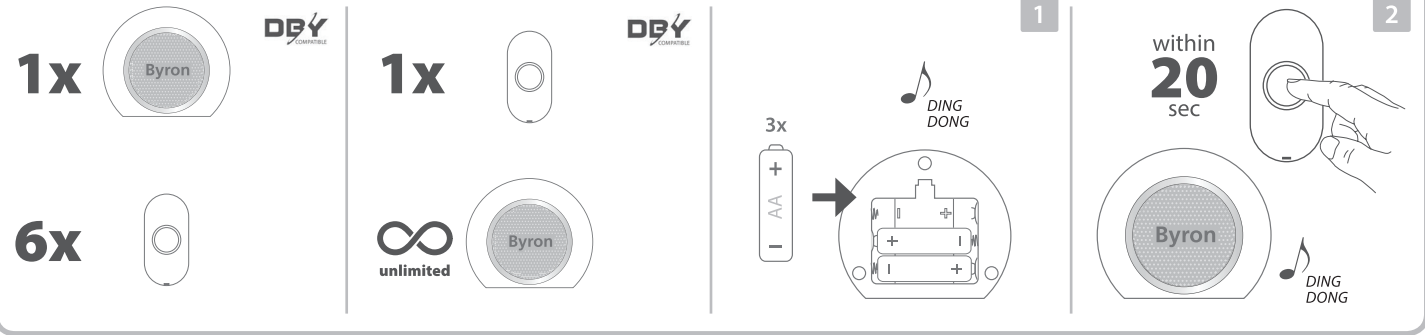

FEATURES | EIGENSCHAFTEN | CARACTÉRISTIQUES | KENMERKEN | CARATTERISTICHE | CARACTERÍSTICAS

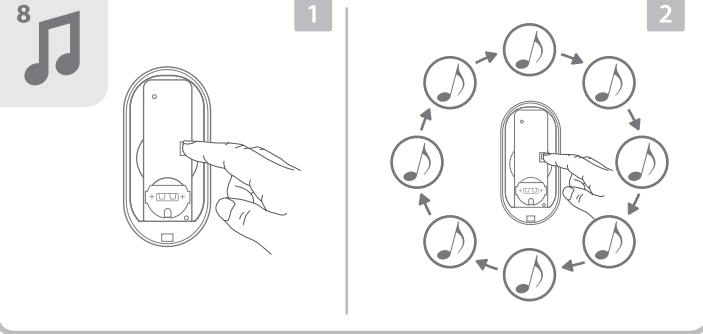

1

2

1

2

Possible in 8 colours

1

1x

3hr

2

2x

6hr

3

3x

9hr

4

4x

12hr

OPTIONAL: ADAPTER 5V -2A | MICRO USB

5

long push

fast

1

2

WARNING:
DO NOT INSERT BATTERIES
WHILE POWERED BY USB

TROUBLESHOOTING | FEHLERBEHEBUNG | RÉOLUTION DE PROBLÈMES | PROBLEMEN OPlossen | RISOLUZIONE DEI PROBLEMI | SOLUCIÓN DE PROBLEMAS

RESET

1

DING DONG

2

within 20 sec.


DING DONG

3

FIRST SET-UP | ERSTEINRICHTUNG | PREMIÈRE CONFIGURATION | EERSTE INSTALLATIE | PRIMO SET-UP | PRIMERA CONFIGURACIÓN

3 and 4

WWW.CHBYRON.EU

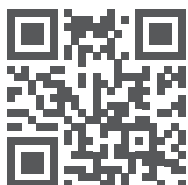

Or contact us directly:

<p>smartwares Europe</p> <p>Jules Verneweg 87 5015 BH Tilburg The Netherlands</p> <p>www.chbyron.eu</p>	NL: 088 5940501	Lokaal tarief
	BE: 078 481094(NL)	Lokaal tarief
	BE: 078 481540(FR)	Tarif local
	FR: 0825 560 650	18ct/min
	DE: +49 (0) 1805 010762	14Ct./Min. dt. Festnetz, Mobil max. 42Ct./Min
	UK: +44 (0) 345 230 1231	
ES: +34 938427589		

CUSTOMER SERVICE

Frequency band: 433.92MHz (433.050 - 434.790 MHz)
Maximum radio-frequency power: +5.92dB
Range: 200 meters

Wireless Doorbell DBY-23521
Power: 3 x AA/LR6 1.5V: Total 4.5V
Indoor Use Only

Push button - DBY-23510
Power supply: 1 x CR2032 3V
IP44 Weather Resistant



Find us on



Conforms to all relevant European Directives.