


Data Sheet

Touch switch

Version 08/20

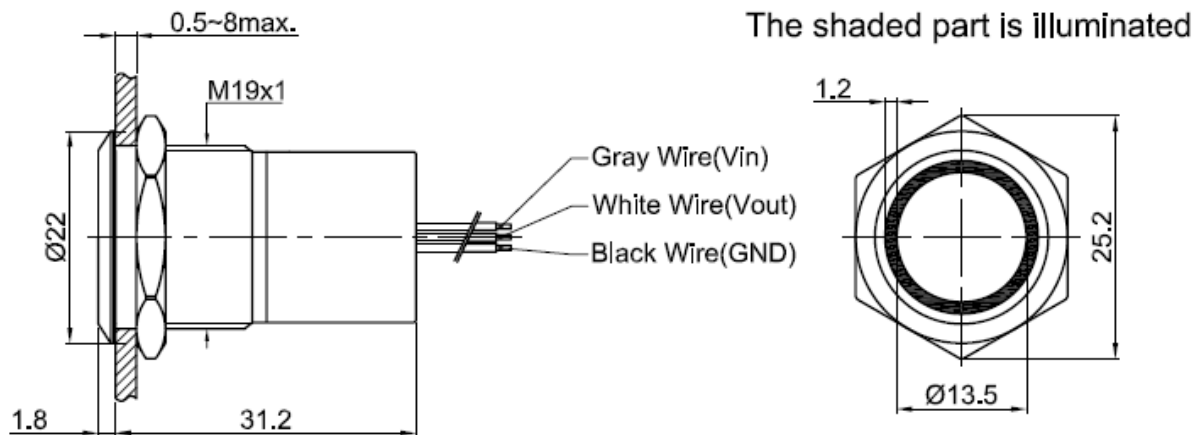

Specification

Mounting diameter	19mm
Operation type	Momentary
Contact structure	1NO
Switch rating	500mA/24VDC
Terminal	Wire
LED	NG(Non illum. / Green) 12V
Body material	Stainless steel
Operating and storage temperature	-25 to +55 °C
Operating and storage humidity	45 to 85 % RH