

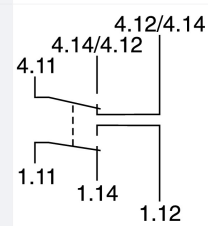


Auxiliary contact, for PLS, postal Code, PKNM, ZP-A40, ZP-ASA, Z-MS, 2W, 0.5HP

Part no. ZP-NHK
Catalog No. 248437

EL-Nummer (Norway) 1609489

Delivery program

Basic function			Accessories for combined residual-current/power circuit-breakers Accessories for miniature circuit-breaker
Basic function accessories			Tripping signal contacts
Application			Switchgear for industrial and advanced commercial applications
Product range			Accessory
Side mounting			for fitting on left to: LS, FI/LS
Contact sequence			

Technical data

Design verification as per IEC/EN 61439

Technical data for design verification			
Operating ambient temperature min.		°C	-5
Operating ambient temperature max.		°C	40

Technical data ETIM 7.0

Devices for distribution board-/surface mounting (EG000062) / Auxiliary device for distribution board devices (EC001286)			
Electric engineering, automation, process control engineering / Electrical installation, device / Breaker switch component / Auxiliary contact unit for distribution board (ec@ss10.0.1-27-14-35-02 [AKE327013])			
Device fitting			Universal
Additional equipment			Signalling switch
Attached at delivery			No
Assembly width (TE)			0.5
Number of contacts as normally open contact			0
Number of contacts as normally closed contact			0
Number of contacts as change-over contact			2
Number of fault-signal switches			0
Rated switch current		A	4
Rated voltage		V	250
Voltage type for actuating			AC
With auto test for earth leakage function			No
Suitable for max. number of poles main contact unit (total)			2
Suitable for max. current main contact unit		A	4

Dimensions

