
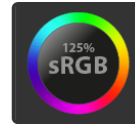


HC 281 HPB

28" / 71,1cm Diagonal
LED Backlight – Format 16:9

- 28" 16:9 LED Backlight Monitor
- 1920 x 1080 Resolution Full HD 1080P
- 170°/160° Wide Viewing Angle
- Dual Input: HDMI + VGA
- Built-In Stereo Speakers
- Tilt and Wall-Mountable (VESA)
- Low Power Consumption
- External Power Adaptor
- Low Blue Light Mode
- Flicker Free
- ECO Friendly
- Wide Color Gamut 125% sRGB, 90% NTSC

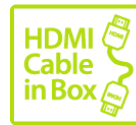

28" / 71,1 cm

Part. No.: HC 281 HPB

SIZE, RESOLUTION



28"
16:9 Aspect Ratio



Full HD
1920 x 1080

CONNECTIVITY, SPEAKER



HDMI
VGA



Built-In
Stereo Speaker

VIEWING ANGLE, VESA



170°/160° Wide
Viewing Angle



VESA
Wall-Mountable

OTHER FEATURES



ECO
Friendly



Low Blue
Light
Mode




Tilt



Flicker
Free

Display Size	71.1cm / 28" Diagonal
Panel Type	LED Backlight TN Panel
Aspect Ratio	16:9
Resolution (H x V)	1920 x 1080 Full HD
Brightness (Typ.)	300cd/m ²
Contrast (Typ.)	1.000:1 (Typical)
Contrast (Active)	10.000.000:1 (Active)
Viewing Angle L/R; U/D	170° H – 160° V (CR >10)
Response Time	5 msec
Pixel Pitch	0,2715 (H) x 0,2715 (V) mm (TBC)
Panel Surface	Anti-Glare; Hard Coating: 3H; Haze: 25%
Display Colors	1.073G (8 bits + High FRC) Wide Color Gamut 125% sRGB, 90% NTSC
Horizontal Frequency	30 ~ 83 kHz
Vertical Frequency	60 ~ 75 Hz
Max Display Frequency	1920 x 1080 @ 60Hz
Input 1	D-Sub (VGA)
Input 2	HDMI 1.4
Input 3	-
Buil-in Speakers	Yes, 2W x 2, 4Ω
Power Consumption	On: 29.9W; Standby: 0.38W; Off: 0.13W
AC Power Range	External PSU DC: 12V – 4A Input: AC 100 ~ 240 Volt; 50 ~ 60 Hz
Product Dimensions	650 x 182 x 463 mm with stand (W x D x H) 650 x 55 x 372 mm without stand (W x D x H)
Packing Dimensions	720 x 110 x 445 mm (W x D x H)
Net / Gross Weight	4.7 Kg / 6.2 Kg

VESA Mounting	Yes, 100 x 100 mm
Monitor Stand	Normal Stand
Tilt / Kensington Lock	-5° ~ +15°(±2°) / Yes
Pivot / Swivel	- / -
Controls	MENU, + / Bri, - / Vol, AUTO / Input, POWER
Color	5500K, 6500K, 9300K, User Modes
Preset Mode	PC, ECO, Game, Movie Modes
Bezel & Color Plan	Front Bezel: Black Texture Rear Cover, Arm & Base: Black Texture
On Screen Display	7 OSD Languages
Accessory	Power Adaptor; Power Cable (1,5m); HDMI Cable (1,5m); Quick Start Guide; Warranty Card
Other Features	Low Blue Light Mode Flicker Free

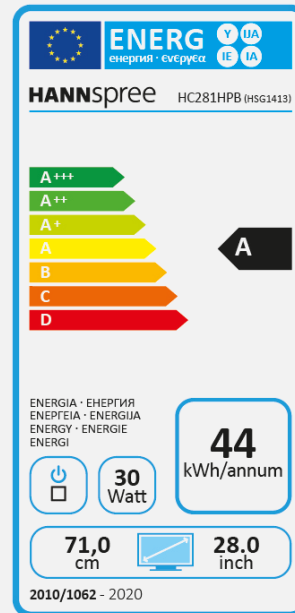

Supplier's Name	HANNspree
Model Name	HC281HPB
Energy Efficiency Class	A
Screen Size (Centimetres)	71
Screen Size (Inches)	28.0
On mode power Consumption (W)	30
Annual Energy Consumption* (kWh)	44
Standby-mode Power Consumption (W)	0,38
Off-mode Power Consumption (W)	0,13
Screen Resolution	1920 x 1080

PART. NO.:
HC 281 HPB

