
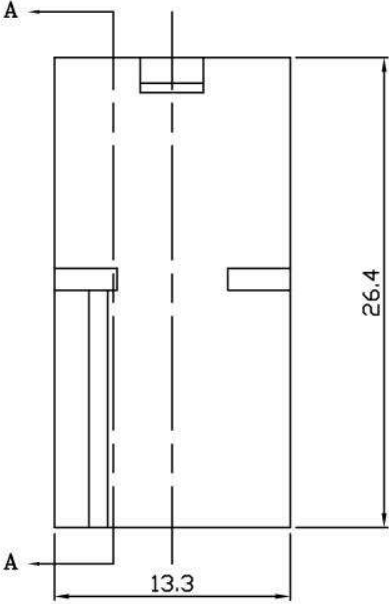
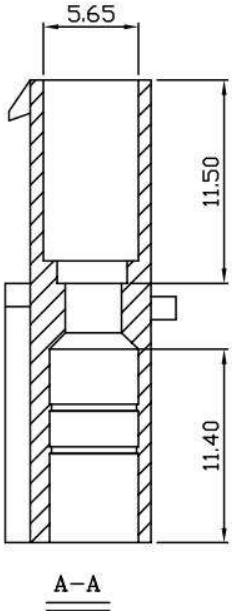


Unit: mm

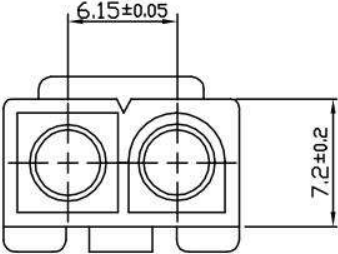

Specifications:

- Poles: 2 Poles
- Current Rating: 5A
- Voltage Rating: 250V AC, DC
- Temperature Range: -25°C~+85°C
- Contact Resistance: Initial value/10mΩ max  
After environmental testing/20mΩ
- Withstand Voltage: 1500V AC/minute
- Insulation Resistance: 1000 MΩ/min
- Material: Nylon UL94V-0·UL94V-2
- Suitable SM 1009T Series Terminal
- Mates With SM 2000H-02 Housing