

# imou




## Cell Pro

### Wire-Free Security System

Cell Pro is a 100% wire-free security system. Powered with rechargeable battery, you can place the camera anywhere, no need to worry about network cabling or power wiring hassles. Thanks to its IP65 weatherproof design you can use the camera either indoor or outdoor in different scenarios.

-  **1080P FHD Video**  
See more than 720P
-  **100% Wire-Free**  
Free of network cabling and power wiring hassles
-  **Rechargeable Battery**  
6 months battery for a full charge\*  
\*Frequent alerts may accelerate battery consumption
-  **PIR Detection**  
High quality passive IR detector for reducing false alerts
-  **Two-way Talk**  
Real-time talk with people in front of the camera
-  **H.265 Codec**  
Save more high-quality video in less space
-  **IP65**  
Weatherproof for outdoor conditions
-  **Cloud Service**  
Live video, storage, alarm alerts and more
-  **Local Backup**  
Connect a USB drive to the base station for local recording backup

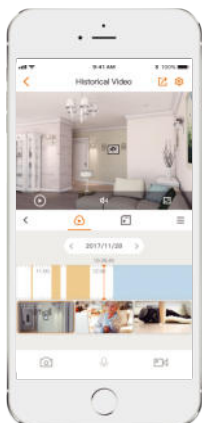

## Stay close with what you care

With Cloud service, you will have access to what you care as long as Internet is available. You can record daily or motion videos on Cloud and playback anytime anywhere.



## Specifications

### Cell Pro

#### Camera

1/2.7" 2 Megapixel Progressive CMOS  
 2MP (1920 x 1080)  
 Night Vision: 10m(33ft) Distance  
 2.8mm Fixed Lens, F2.2  
 Field of View : 110° (H), 61° (V), 130° (D)

#### Video

Video Compression : H.265/H.264  
 Up to 20fps Frame Rate

#### Notice Management

PIR Detection

#### Network

Wi-Fi: IEEE802.11b/g/n,50m(164ft) Open Field  
 Imou App: iOS, Android

### Base Station

#### Network

1 x 100Mbps Ethernet Port  
 Wi-Fi: IEEE802.11b/g/n, 100m(328ft) Open Field, 2 X 2 MIMO

#### Auxiliary Interface

1 x DC Power Port	1 x LAN Port
1 x Reset Button	1 x USB2.0 Port
1 x Sync Button	

#### Auxiliary Interface

Built-in Mic & Speaker  
 Micro USB Power Port  
 SYNC Button

#### General

DC 5V 1A Power Supply or Rechargeable Battery Power  
 6 Months Battery for a Full Charge  
 Power Consumption: ≤3W  
 IP65  
 Working Environment: -20°C~+45°C (-4°F~113°F),  
 Less Than 95%RH  
 Dimension: 77 x 77 x 71.5mm(3.03 x 3.03x 2.81 inch)  
 Weight: 350g(0.77lb)  
 CE, FCC, UL

#### General

DC 12V 2A Power Supply  
 Power Consumption: ≤6W  
 Working Environment: -10°C~+50°C (14°F~122°F),  
 Less Than 90%RH  
 Dimension: 157 x 108 x 154mm(6.18 x 4.25 x 6.06 inch)  
 Weight: 270g(0.60lb)

## Purchase Options

---

### Cell Pro Kit (1 Base Station + 1 Camera)



#### What's in the box

- |                   |                       |
|-------------------|-----------------------|
| 1 x Camera        | 1 x Base Station      |
| 1 x Power Cable   | 1 x Power Adapter     |
| 1 x Bracket       | 1 x Network Cable     |
| 1 x Battery       | 1 x Quick Start Guide |
| 1 x Screw Package | 1 x Positioning Map   |

### Cell Pro Kit (1 Base Station + 2 Cameras)



#### What's in the box

- |                    |                       |
|--------------------|-----------------------|
| 2x Cameras         | 1 x Base Station      |
| 2 x Brackets       | 1 x Power Adapter     |
| 2 x Batteries      | 1 x Network Cable     |
| 2 x Screw Packages | 1 x Quick Start Guide |
| 1 x Power Cable    | 1 x Positioning Map   |

### Cell Pro (Add on Camera)



#### What's in the box

- |                       |                          |
|-----------------------|--------------------------|
| 1 x Camera            | 1 x Positioning Map      |
| 1 x Quick Start Guide | 1 x Screw Package        |
| 1 x Power Cable       | 1 x Rechargeable Battery |
| 1 x Bracket           |                          |