



CAT.6A S/FTP PUR Patch Cable

Technical Features

Industrial Use, IP20

CAT.6A Class EA S/FTP

4x2x27/7 AWG stranded copper wire

Acid Resistant

UV Resistant

Hydrolysis Resistant


Halogen Free (conform IEC 60754-2)

Oil Resistant (conform EN 60811-2-1)

Low Smoke (conform IEC 61034)

Max. Operating Temperature -40°–90°

Technical Drawing

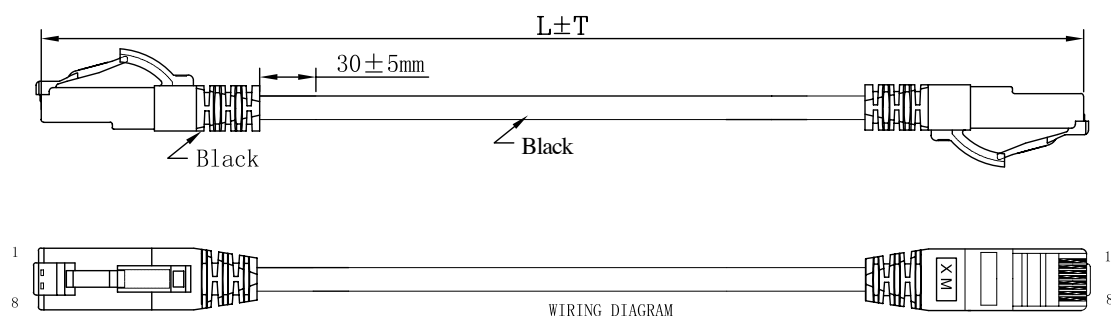

P 1		P 2	
1	—	1	WHITE
2	—	2	ORANGE
3	—	3	WHITE
6	—	6	GREEN
4	—	4	BLUE
5	—	5	WHITE
7	—	7	WHITE
8	—	8	BROWN
shell	braid	shell	

www.2direct.de



RoHS
compliant



Made in China

*The specifications and pictures are subject to change without prior notice.
*All trade names referenced are the registered trademarks of their respective owners.

Length	Black	EAN Code
0.50 m	CQ6025S	4052792049763
1.00 m	CQ6035S	4052792049770
2.00 m	CQ6055S	4052792049787
3.00 m	CQ6065S	4052792049794
5.00 m	CQ6075S	4052792049800
7.50 m	CQ6085S	4052792049817
10.00 m	CQ6095S	4052792049824
15.00 m	CQ6105S	4052792049831
20.00 m	CQ6115S	4052792049848
30.00 m	CQ6125S	4052792049855
40.00 m	CQ6135S	4052792049862
50.00 m	CQ6145S	4052792049879

Package Content

1x CAT.6A S/FTP PUR Patch Cable

Packaging Information

Art-No.	Packing Dimension	Packing Weight	Carton Dimension	Carton Q'ty	Carton Weight
CQ6025S	100x100x10 mm	0.036 kg	400x300x300 mm	260 pcs	10.4 kg
CQ6035S	100x100x15 mm	0.053 kg	400x300x300 mm	200 pcs	11.6 kg
CQ6055S	110x110x20 mm	0.087 kg	400x300x300 mm	100 pcs	9.7 kg
CQ6065S	125x125x30 mm	0.118 kg	400x300x300 mm	80 pcs	10.5 kg
CQ6075S	120x120x30 mm	0.182 kg	400x300x300 mm	55 pcs	11 kg
CQ6085S	135x135x35 mm	0.274 kg	400x300x300 mm	45 pcs	13.3 kg
CQ6095S	140x140x40 mm	0.35 kg	400x300x300 mm	30 pcs	11.5 kg
CQ6105S	160x160x50 mm	0.531 kg	400x300x300 mm	25 pcs	13.8 kg
CQ6115S	150x150x60 mm	0.699 kg	400x300x300 mm	18 pcs	13.6 kg
CQ6125S	180x180x60 mm	1.039 kg	400x300x300 mm	14 pcs	15.1 kg
CQ6135S	180x180x60 mm	1.379 kg	400x300x280 mm	12 pcs	17 kg
CQ6145S	190x190x75 mm	1.719 kg	400x300x280 mm	10 pcs	17.6 kg

www.2direct.de



RoHS
compliant



Made in China

*The specifications and pictures are subject to change without prior notice.
*All trade names referenced are the registered trademarks of their respective owners.