



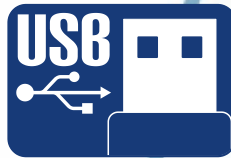

RU-275

PORTABLE FM RADIO WITH USB / SD,
AUX-IN AND HEADPHONES OUT.

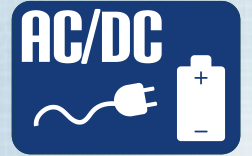

RU-275/BK



RU-275/WH



RU-275

PORTABLE FM RADIO WITH USB / SD,
AUX-IN AND HEADPHONES OUT.



CD PLAYER

Loader type
Electronic Shock Protection
Compressed audio playback
Disc support
Auto ID3 tag detection
MP3 search by
Data rate system
Fast forward / reverse
Track search
Intro scan
Random play
Repeat track / album
Program function

TUNER

Tuner type	PLL
Ranges (band)	FM
RDS system / Radiotext	
Preset stations	10
Stereo / Mono selector	(Stereo)
Automatic tuning	
Manual tuning	•

CASSETTE

Cassette deck
Cassette mechanism
Automatic Level Control (ALC)
One Touch Recording (OTR)
Built-in microphone

USB/SD/MMC

Encoding	
Playback	•
Copy	
Delete	
iPod compatibility	

TURNTABLE

R.P.M.
Tone Arm Mechanism

CONNECTIONS

Bluetooth	
USB port	•
Card slot	•
Aux in	Ø 3.5mm Jack
Line Out	
Headphones Out	Ø 3.5mm Jack

AUDIO

Speaker system	2 speakers
Total PMPO Output Power	16 Watt
Nominal Output Power	2 x 1 Watt rms
Volume control	Analog
Equaliser	

GENERAL

Accessories included	AC Cord
Colour Versions	BK - Black WH - White
Display / Illumination	LCD
Power supply	230V AC / 4 x "LR14" Batteries

Battery Memory	
Weight	Kg
Dimensions (WxLxH)	175x245x100 mm

COMMERCIAL

Container load 40'	9'280 pcs
Container load 20'	4'640 pcs
Shipping carton	4 pcs
Gift Box size (WxLxH)	182x246x110 mm
Shipping car. size (WxLxH)	378x276x238 mm

EAN code

RU-275/BK	7621800032676
RU-275/WH	7621800032683

Master Carton EAN code

RU-275/BK	7621800054593
RU-275/WH	7621800054609
Country of origin	P.R.C.