



NEW

RCR-3025EBT

PORTABLE CASSETTE RECORDER WITH AM / FM / SW TUNER, BLUETOOTH FUNCTION, USB / SD CARD PORT AND HEADPHONES OUT.



DIRECT USB/SD ENCODING

RECORDING FUNCTION TO CASSETTE




RCR-3025EBTRD

RCR-3025EBTBK



RCR-3025EBTBL

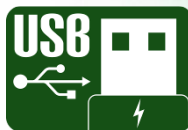

PORTABLE AUDIO

RCR-3025EBT

PORTABLE CASSETTE RECORDER WITH AM / FM / SW TUNER, BLUETOOTH FUNCTION, USB / SD CARD PORT AND HEADPHONES OUT. RECORDING FUNCTION TO CASSETTE. ENCODING FUNCTION TO USB / SD CARD.



CD PLAYER

Loader type
Electronic Shock Protection
Compressed audio playback
Disc support
Auto ID3 tag detection
MP3 search by
Data rate system
Fast forward / reverse
Track search
Intro scan
Random play
Repeat track / album
Program function

TUNER

Tuner type	Analog
Ranges (band)	AM/FM/SW1/SW2
RDS system / Radiotext	
Preset stations	
Stereo / Mono selector	
Automatic tuning	
Manual tuning	•

CASSETTE

Cassette deck	•
Cassette mechanism	Autostop
Automatic Level Control (ALC)	
One Touch Recording (OTR)	
Built-in microphone	•

USB/SD/MMC

Encoding	•
Playback	•
Copy	
Delete	
iPod compatibility	

TURNTABLE

R.P.M.
Tone Arm Mechanism

CONNECTIONS

Bluetooth	•
USB port	3.0 (max 32GB)
Card slot	SD (max. 32GB)
Aux in	
Line Out	
Headphones socket	Ø 3.5mm Jack

AUDIO

Speaker system	2 speaker
Total PMPO Output Power	24 Watt
Nominal Output Power	2 x 1.5 Watt RMS
Volume control	Analog
Preset equaliser	

GENERAL

Accessories included	AC cord
Colour Versions	BK - Black RD - Red BL - Blue
Display / Illumination	LCD / Amber
Power supply	AC 230 V, 50Hz DC 6V (4 x "LR20")

Battery Memory	
Weight	1.24 Kg
Dimensions (WxLxH)	312x110x120 mm

COMMERCIAL

Container load 40'	8'628 pcs
Container load 20'	4'308 pcs
Shipping carton	6 pcs
Gift Box size (WxLxH)	380x119x141 mm
Shipping car. size (WxLxH)	392x375x297 mm

EAN code

RCR-3025EBTBK	7621800032805
RCR-3025EBTRD	7621800032898
RCR-3025EBTBL	7621800032881

Master Carton EAN code

RCR-3025EBTBK	7621800054715
RCR-3025EBTRD	7621800054791
RCR-3025EBTBL	7621800054784
Country of origin	P.R.C.