





# HRA-9D+BT-Wood


HOME DAB+ / FM RADIO WITH CD-MP3, BLUETOOTH, USB AND AUX-IN.

ENCODING FROM DAB / CD /  
BLUETOOTH / AUX TO USB


240 W PMPO (2 X 15 Wrms)

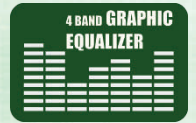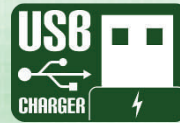

CD PLAYER

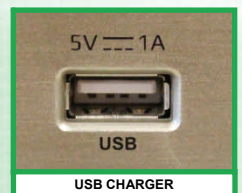

USB CHARGER

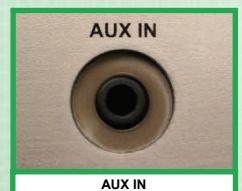

AUX IN



REMOTE CONTROL

HRA-9D+BT/WD



HRA-9D+BT/BK

HOME RADIO

# HRA-9D+BT-Wood

HOME DAB+ / FM RADIO WITH CD-MP3,  
BLUETOOTH, USB AND AUX-IN.



## CD PLAYER

Loader type	Front Drawer
Electronic Shock Protection	
Compressed audio playback	MP3
Disc support	CD-CDR-CDRW
Auto ID3 tag detection	
MP3 search by	Track
Data rate system	
Fast forward / reverse	•
Track search	•
Intro scan	
Random play	•
Repeat track / album	•
Program function	•

## TUNER

Tuner type	Digital
Ranges (band)	DAB / DAB+ / FM
RDS system / Radiotext	•
Preset stations	20
Stereo / Mono selector	(Stereo)
Automatic tuning	•
Manual tuning	•

## CASSETTE

Cassette deck	
Cassette mechanism	
Automatic Level Control (ALC)	
One Touch Recording (OTR)	
Built-in microphone	

## USB/SD/MMC

Encoding	From DAB, CD, Bluetooth and AUX.
Playback	•
Copy	•
Delete	•

iPod compatibility

## TURNTABLE

R.P.M.	
Tone Arm Mechanism	

## CONNECTIONS

Bluetooth	•
USB port	•
Card slot	
Aux in	Ø 3.5mm Jack
Line Out	
Headphones socket	

## AUDIO

Speaker system	2 speakers
Total PMPO Output Power	240 Watt
Nominal Output Power	2 x 15 Watt rms
Volume control	Analog
Preset equaliser	Flat, Classic, Rock, Pop, Jazz

## GENERAL

Accessories included	Remote Control, Wired Antenna
Colour Versions	BK - Black Wood WD - Wood
Display / Illumination	LCD / Blue
Power supply	230V AC
Battery Memory	
Weight	3.4 Kg
Dimensions (WxLxH)	350x260x135 mm

## COMMERCIAL

Container load 40' HQ	2350 pcs
Container load 40'	1876 pcs
Container load 20'	972 pcs
Shipping carton	2 pcs
Gift Box size (WxLxH)	400x350x180 mm
Shipping car. size (WxLxH)	420x370x370 mm

## EAN code

HRA-9D+BT/BK	7621800032478
HRA-9D+BT/WD	7621800032485

## Master Carton EAN code

HRA-9D+BT/BK	7621800054395
HRA-9D+BT/WD	7621800054401
Country of origin	P.R.C.