




CLR-290D+

DAB+ / FM CLOCK RADIO WITH DUAL ALARM, SLEEP TIMER, LCD NEGATIVE DISPLAY MULTI LANGUAGES, USB PORT FOR CHARGING, 3.5MM HEADPHONE JACK

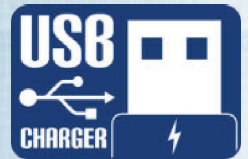

CLR-290D+/BK



CLR-290D+/WH

CLOCK RADIO

CLR-290D+

DAB+ / FM CLOCK RADIO WITH DUAL ALARM, SLEEP TIMER, LCD NEGATIVE DISPLAY MULTI LANGUAGES, USB PORT FOR CHARGING, 3.5MM HEADPHONE JACK



CD PLAYER

Loader type
Electronic Shock Protection
Compressed audio playback
Disc support
Auto ID3 tag detection
MP3 search by
Data rate system
Fast forward / reverse
Track search
Intro scan
Random play
Repeat track / album
Program function

TUNER

Tuner type	Digital
Ranges (band)	DAB / DAB+ / FM
RDS system / Radiotext	•
Preset stations	40 DAB, 40 FM
Stereo / Mono selector	(MONO)
Automatic tuning	•
Manual tuning	•

CASSETTE

Cassette deck
Cassette mechanism
Automatic Level Control (ALC)
One Touch Recording (OTR)
Built-in microphone

USB/SD/MMC

Encoding
Playback
Copy
Delete
iPod compatibility

TURNTABLE

R.P.M.
Tone Arm Mechanism

CONNECTIONS

Bluetooth	
USB port	FAST CHARGING 1A RATING
Card slot	
Aux in	
Line Out	
Headphones socket	Ø 3.5mm Jack

AUDIO

Speaker system	speaker
Total PMPO Output Power	16 W
Nominal Output Power	1 x 2.0 Wrms
Volume control	Digital
Preset equaliser	

GENERAL

Accessories included	AC / DC Adapter 5V 1A OUTPUT
Colour Versions	Black or White
Display / Illumination	LCD NEGATIVE DISPLAY with icons
Power supply	230V AC
Battery Memory	
Weight	1.7 Kg
Dimensions (WxHxD)	320x55x285 mm

COMMERCIAL

Container load 40'	pcs
Container load 20'	pcs
Shipping carton	10 pcs
Gift Box size (WxHxD)	238x158x55 mm
Shipping car. size (WxHxD)	292x332x258 mm

EAN code

CLR-290D+/BK	7621800032966
CLR-290D+/WH	7621800032973

Master Carton EAN code

CLR-290D+/BK	7621800054852
CLR-290D+/WH	7621800054869

Country of origin	P.R.C.
-------------------	--------