



## Dome Lite 4MP

### 4MP H.265 Dome Wi-Fi Camera

Dome Lite 4MP delivers 4MP live monitoring with a choice of 2.8mm or 3.6mm lens option, it supports the latest H.265 compression which can save up to 50% bandwidth and storage. Real-time motion detection and instant alert keep you aware of what is happening to your belongings at anytime from anywhere.



#### 4MP QHD Video

See more than 1080P



#### 24/7 Protection

Infrared night vision for clear-as-day clarity even in pitch dark



#### H.265 Codec

Save more high-quality video in less space



#### Alarm Notification

Sends instant motion-activated alerts to your mobile phone



#### Micro SD Card Slot

Supports up to 128GB local storage




#### Wi-Fi Connection

IEEE802.11b/g/n(2.4GHz)



#### Cloud Service

Live video, storage, and more

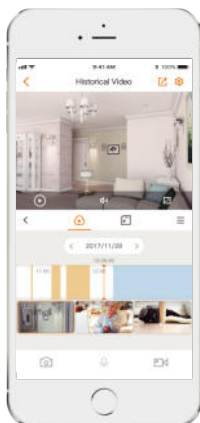

## Stay close with what you care

With Cloud service, you will have access to what you care as long as Internet is available. You can record daily or motion videos on Cloud and play back anytime anywhere.

## Specifications

---

### Camera

1/3" 4 Megapixel Progressive CMOS  
4MP(2560 x 1440)  
Night Vision: 20m(65ft) Distance  
2.8mm or 3.6mm Fixed Lens  
Field of View : 2.8mm: 97° (H), 52° (V), 115° (D)  
3.6mm: 76.4° (H), 41.6° (V), 89.5° (D)

### Video & Audio

Video Compression : H.265/H.264  
Up to 20fps Frame Rate  
16x Digital Zoom

### Notice Management

Motion Detection  
Configurable Region

### Network

1 x 100Mbps Ethernet Port  
Wi-Fi:IEEE802.11b/g/n,50m Open Field  
Imou App: iOS, Android  
CGI, ONVIF

### Auxiliary Interface

Micro SD Card Slot (up to 128GB)  
Reset Button

### General

DC 12V1A Power Supply  
Power Consumption:<4.7W  
Material: Plastic  
Working Environment:-20° C~+45° C, Less Than 95%RH  
Dimensions: Φ100 × 74.3mm (3.9 × 2.9 inch)  
Weight: 195g (0.43lb)  
CE, FCC, UL

## What's in the box

---

- 1x Camera
- 1x Quick Start Guide
- 1x Power Adapter

- 1x Screw Package
- 1x Installation Position Map

