


CAN adapter cable 0.2 m (D-Sub 9 to RJ45)

Adapter cable for USB-to-CAN V2 interfaces, to convert the RJ45 socket to a CiA compliant D-Sub 9 plug.

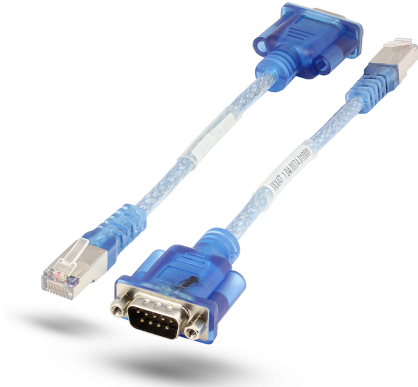

FEATURES AND BENEFITS

- RJ45 male to 9-pin D-Sub male
- Length 10 cm (cable); total length 20 cm
- Set of two cables

ORDER NUMBER	1.04.0074.01000
CAN connector	D-Sub 9 plug to RJ45 plug
Length	20 cm

PIN ALLOCATION

RJ45	-	D-Sub 9	Signal (If used in conjunction with USB-to-CAN II)
1	-	7	CAN high
2	-	2	CAN low
3	-	3	GND
4	-	4	CAN high (Fault tolerant, only automotive)
5	-	1	CAN low (Fault tolerant, only automotive)
6	-	5	LIN (only automotive)
7	-	6	GND
8	-	9	V-LIN (12V DC, max. 200mA, only automotive)
n.a.	-	8	-
Shield	-	Shield	-

TECHNICAL DRAWING

