


Data Sheet

Description name: Thermal Foil 70 x 50 mm

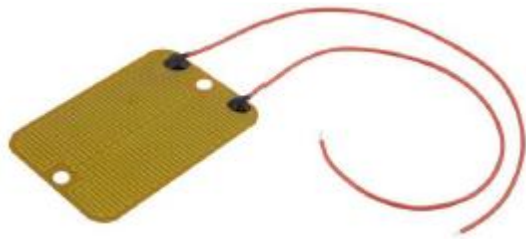

Size: 70 x 50 mm

Voltage: 12 V/DC

Power: 2 W

Material: Polyimide (PI)

Thickness: 0.3 mm +/-0.02 mm (including adhesive) Operation Temp:-20 °C~100 °C

Operation Humidity: 10%~100%

Storage Temp: -20 °C~100 °C

Storage Humidity: 10%~100%

Max surface temperature: 250 °C

Element resistance: 64.8-79.2 Ω

Watt density chart: 2 W

Max. Power/cm²: 0.5 W/CM²

Polyimide: 50 x 70 x 0.05 mm (2PCS)

Alloy Heating wire: 50 x 70 x 0.04 mm (1PCS) Cable:UL3239# 22AWG Red L=200 mm
(2PCS) 3M467 adhesive(1PCS)