


## Data Sheet

---

### Description name: Thermal Foil 60 x 60 mm

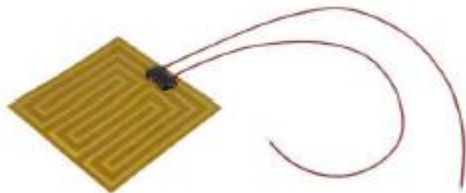

Size:60\*60mm

Volage:12V

Power:48W

Material: Polyimide (PI)

Thickness: 0.3mm +/-0.02mm (including adhesive) Operation Temp:-20C~100C

Operation Humidity: 10%~100%

Storage Temp: -20C~100C

Storage Humidity: 10%~100%

Max surface temperature: 250C

Element resistance: 2.7-3.3Ω

Watt density chart: 48W

Max. Power/CM2: 0.5W/CM2

Polymide: 50\*70\*0.05mm (2PCS )

Alloy Heating wire: 50\*70\*0.04mm (1PCS )

Cable:UL1332# 22AWG Red L=200mm (2PCS ) 3M467 adhesive(1PCS)