
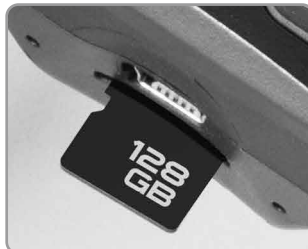


## FullHD Binoculars with Display TX-142

Integrated camera with 4x zoom and color display

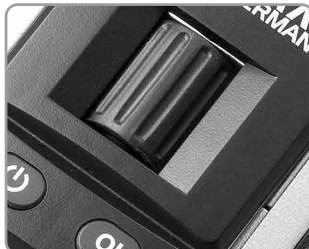

- FullHD Binoculars for taking videos or photos
- FullHD 1080P(30fps) for videos
- 2592x1944 (JPG) for photos
- Digital zoom up to 4x magnification
- Low light amplification (better view at low light (0.01 lux)
- Supports MicroSD card up to max.128GB
- Built in 2500mAh rechargeable battery (up to 8h recording)
- 7h of 1080p (30fps) video recordings equal ≈ 32GB
- Optical glass with 12x magnification
- Distance covered: from 96 to 1000 meters

### Technical Specifications:

- 1/2,8" CMOS Sensor 5MP
- Lens: f=25mm, F/NO 3.0, FOV=17,5°, low light amplification (0.01 lux)
- Video resolution: 1920x1080/30fps, 1280x720/60fps, 1280x720/30fps
- Photo resolution: 5MP: 2592x1944, 3MP: 2048x1536, VGA: 640x480
- Video length: 1, 3, 5 or 10 min. settable
- File format: JPG/MP4
- 1x type 18650 lithium battery (built in) 3.7V, 2500mAh
- Working time: Video: 7-8h; Photo: Depending on the resolution
- MicroSD\*\* card (up to 128GB, Class10) [\*\*not included]
- Video recording: 1080p: 5min. ≈ ca. 250MB; ca. 7h ≈ 32GB
- Photo recording: 5M: 1x photo ≈ 2MB; ca. 15000 ≈ 32GB
- Working temperature: -7°C up to +40°C
- Weight / Dimensions: 485g / (L) 14.5 x (W) 11.5 x (H) 5.5cm

### Package Contents:

FullHD Binoculars with Display TX-142, 1x Mini USB cable, 1x Neckstrap, 1x Cloth, User manual



Article No. 4863

