


HEAR IN COLOR

1MORE ColorBuds





Qualcomm aptX™

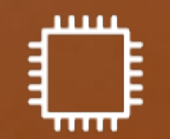

Qualcomm Chip
Stable Connection



Dual ENC
Microphones



Ergonomic Fit



Full Range
Balanced Armature



aptX / AAC



Fast Charge
15 Min = 2 H



Auto Pairing



Auto Pause / Play

 


IPX5 Water / Sweat
Resistant




SHOW YOUR TRUE COLORS

Stand out from the crowd with dazzling colors and a sleek metallic finish thanks to a NCVM (non-conductive vacuum metallization) color-coating process.



NCVM
Zero Signal Interference

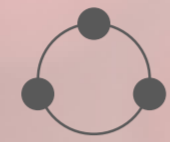

Sweatproof
Wear Resistant
Long-Lasting Color



Twilight
Gold



Spearmint
Green



Sakura
Pink



Midnight
Black

SOUND THAT TRAVELS

Enjoy a lightweight and compact design with a portable charging case that fits easily in your pocket for enhanced portability. With each earbud weighing only 4.1 g, you'll forget you are even wearing them.

Each earbud weighs only

4.1g



IMPROVED ERGONOMIC DESIGN

Having a tight seal is especially important for your earbuds. The oblique-angled nozzles provide a comfortable and secure fit during those long work-days or rigorous exercises.



Non-contact tip
Prevents friction

Reduces ear fatigue

Stable support end



EVERY NOTE COMES ALIVE

The ColorBuds feature a unique full-range balanced armature that provides less distortion across the entire sound curve. From crisp highs to punchy bass, hear what it's like to listen to your favorite music for the first time again.



TUNED TO PERFECTION

Tuned by Grammy® winning sound engineer Luca Bignardi for a fully balanced and precise soundstage.



Luca Bignardi
4-time Grammy Award winner




LET YOUR VOICE BE HEARD

Qualcomm cVc 8.0 dual microphones feature Environmental Noise Cancellation (ENC) technology which suppresses ambient noise so your voice remains crystal clear even in loud environments.

ENC Microphone



Talking
Microphone

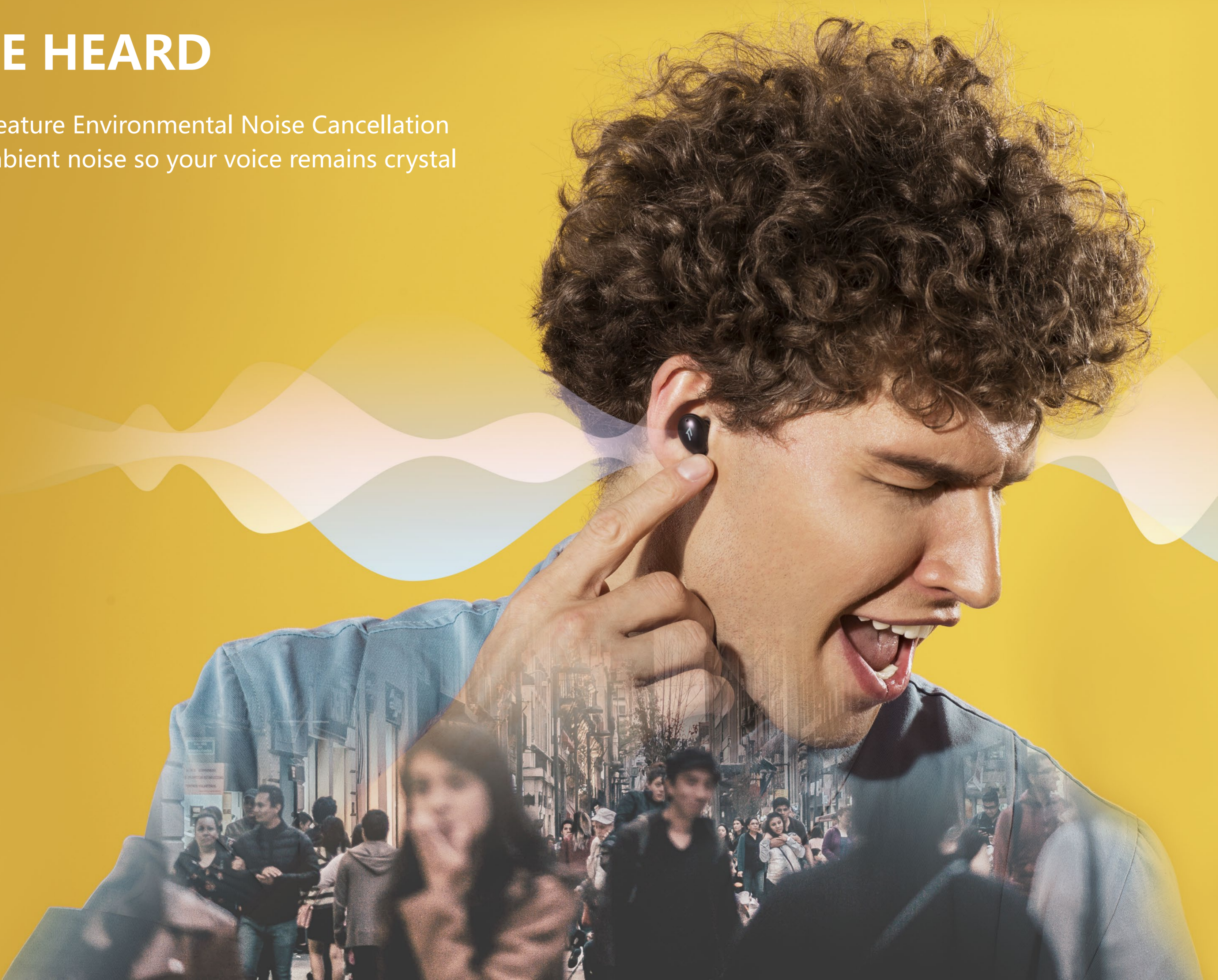

AUTO PAUSE & PLAY

Built-in infrared sensors automatically play or pause music when taken in or out of your ears so you can pick up right where you left off with ease.

*Auto-play function can be disabled in the 1MORE Music app.



Infrared Sensor

IPX5 WATER & SWEAT RESISTANCE

Built to handle even the toughest situations you throw at them, these earbuds feature IPX5 water & sweat resistance to provide all-around protection against outdoor conditions and workouts.



STAY CONNECTED

Integrated with a Qualcomm chipset and a powerful LDS antenna, experience a fast and stable connection in high density environments with the latest Bluetooth® 5 technology.



Professional
Qualcomm chip
Stable connection



Bluetooth® 5
Less power consumption.
Wider coverage



LDS Antenna
Less signal interference



PREMIUM SOUND FOR ANY DEVICE

Compatibility with aptX and AAC Bluetooth codecs ensures the best possible wireless audio quality on virtually any device.

aptX

Premium wireless sound
for Android devices



AAC

Optimized sound
quality for iOS devices



EXTENDED BATTERY LIFE

Enjoy 6 hours of non-stop music on a single charge and extend it to 22 hours with the included portable charging case.

330

Songs

14

Movies

16,000

Kilometers Flight



*The playtime is tested under AAC format at 50% volume.

CHARGE LESS, HEAR MORE.


Built with fast charge functionality, these earbuds can get an additional 2 hours of use on only 15 minutes of charge time.

 **15** =  **2**
MINUTES HOURS



HASSLE-FREE PAIRING

After initial pairing, these earbuds will automatically pair to your device as soon as you open the case lid. Yes, it's that easy.

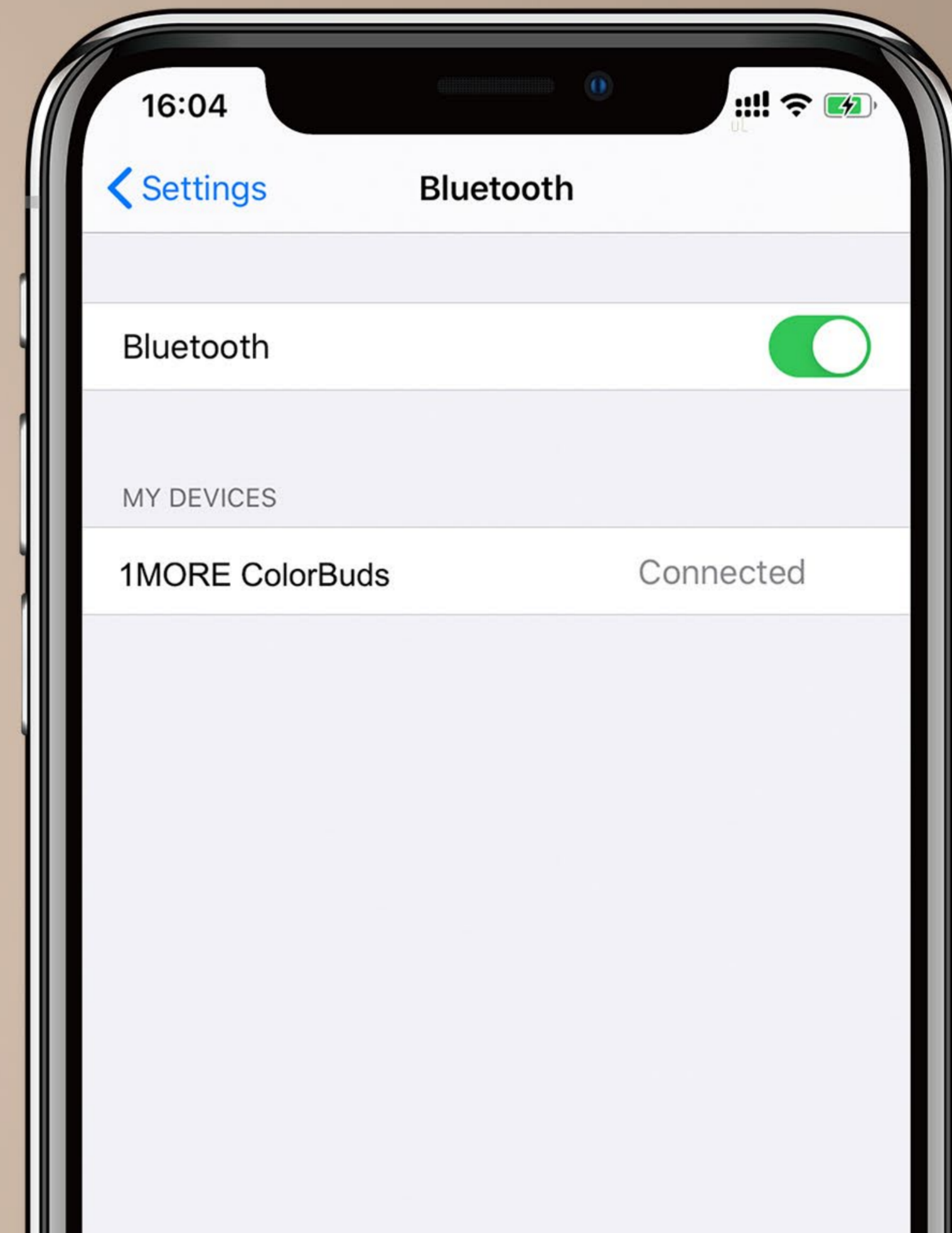

CONVENIENT TOUCH CONTROL



Answer: Double Tap
Hang Up: Double Tap



Play: Double Tap
Pause: Double Tap



Activate Voice Control:
Triple Tap

SPECIFICATIONS

Model:	ESS6001T	Earbud Battery Capacity (Single):	55 mAh
Single Earbud Weight:	4.1 g	Case Battery Capacity:	410 mAh
Case Weight:	32.1 g	Earbud Charging Time:	70 Mins
Gross Weight:	40.3 g	Case Charging Time:	85 Mins
Earbud Dimensions:	27 × 21 × 20 mm	Playtime	
Case Dimensions:	60 × 30 × 38 mm	* Earbuds Fully Charged	
Speaker Impedance:	22 Ω	Call:	6 Hours
Bluetooth Range:	10 m	Music Playtime :	6 Hours
Audio Format:	aptX / AAC / SBC	* Earbuds and Case Fully Charged	
Bluetooth:	Bluetooth® 5	Phone Call:	22 Hours
Bluetooth Protocol:	HFP / A2DP / AVRCP	Music Playtime:	22 Hours
Input:	5V 1A		

* Above data is from 1MORE lab.

The playtime is tested under the laboratorial condition with AAC format at 50% volume which may vary according to factors like device settings, environmental or use habits.