



ROTARY SWITCH

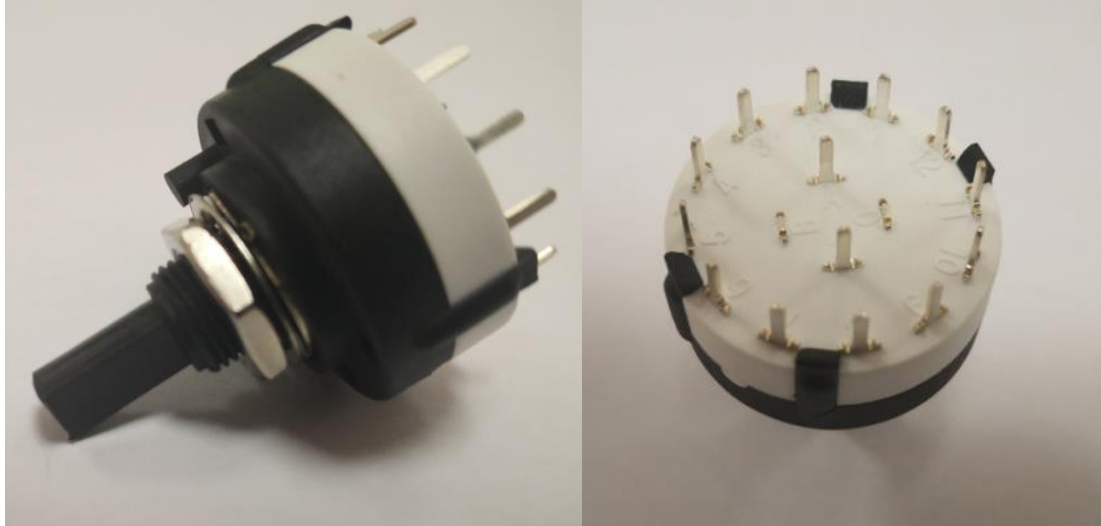

SR26B4

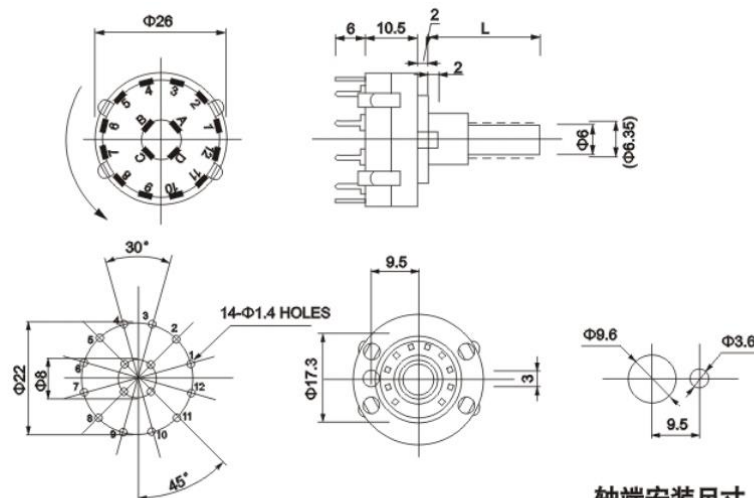


线路板开孔尺寸
The tapping size of circuit board

轴端安装尺寸
The fitting size of shaft end

Data Sheet

Shaft type:F

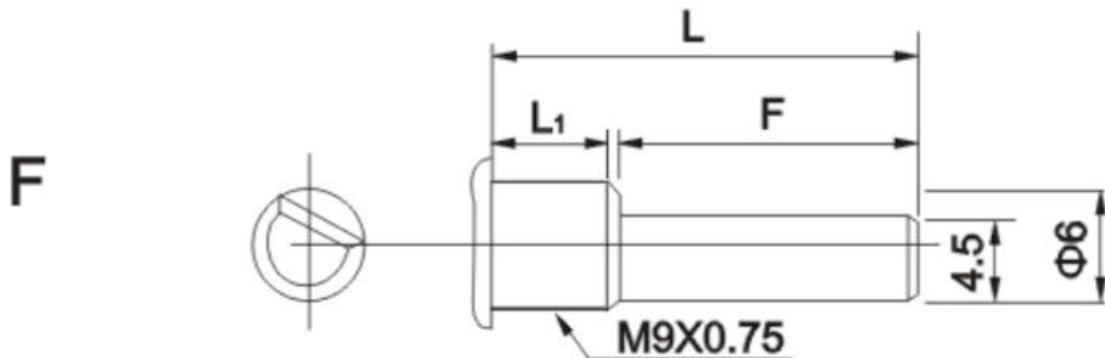

L1:7mm F:13mm L:20mm

Technical data

Switch Rating	150mA at 250VAC/DC 300mA at 125VAC/DC
Contact resistance	≤0.05Ω (initial)
Insulation Resistance	DC 500V-1000MΩ Min
Limited voltage	AC 500V-1Min
Proof voltage	1,000 VAC(initial)
Rotation torque	4.9-24.5 N.cm
End stop strength	49 N.cm
Mechanical endurance	≥10000cycles
Ambient temperature	-21°C~70°C
Welding hear-resistant property	260 °C/ 2.5±0.5S